
 
 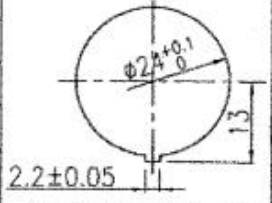



# Data Sheet




## Rocker Switch



Rating	25A 12V DC	Mounting Hole	Circuit Diagram
Contact Resistance	50m ohm Max.	 <p>2.2±0.05 Thickness 1~4 mm</p>	OFF 
Insulation Resistance	DC 500V 100M ohm Min.		ON 
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20° C ~ 65° C		
Switch Function	3P SPST ON-OFF (LED dependent)		

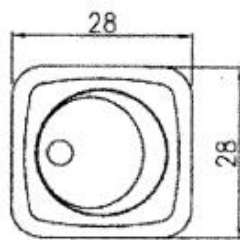

Material:  
 Frame: Nylon 66 , Black  
 Actuator: Nylon 66 +33%GF, Black  
 LED: Red

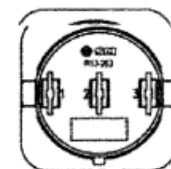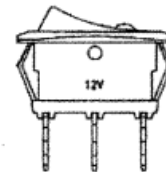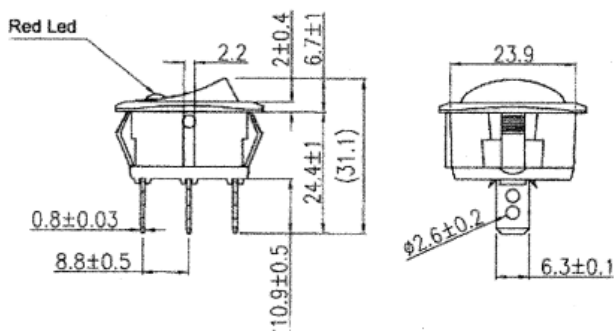

## Data Sheet

---

Tolerances  $\pm 0.3$  Unless Otherwise Specified

Connection	Type C CEE 7/16 plug 6.3 mm
Lighting type	Spot lighting
Light colour	Red
Bulb type	LED
Print motif	None
Colour	Black
Switching voltage	12 Vdc
Switching current (max.)	25 A
Number of pins	1
Switch position	1 x Off/On
Functions	latch
Recess diameter	24 mm
Front panel thickness	Max4 mm