


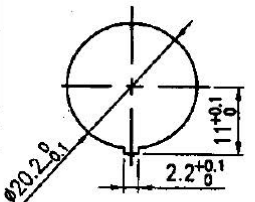
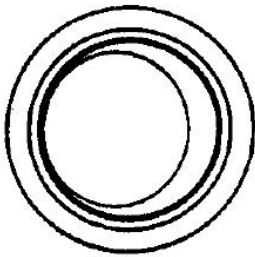







Rocker Switch

Rating	10(4)A 250V~ 	Mounting Hole
	16A 125V AC  10A 250V AC	
	10A 28VDC  6A 14VT	
Contact Resistance	50m ohm Max.	 Panel Thickness 2.0~3.0 mm
Insulation Resistance	DC 500V 100M ohm Min.	
Dielectric Strength	AC 1500V 1 minute	
Operation Temperature	-20°C~125°C	
Switch Function	2P SPST ON-OFF	



*Material
 Frame: Nylon#66,Black
 Actuator: Nylon#66,Black
 Terminal: Copper alloy,Silver plated

 Diagram

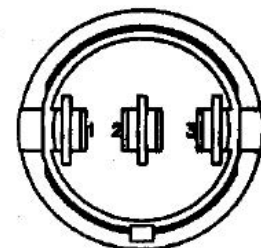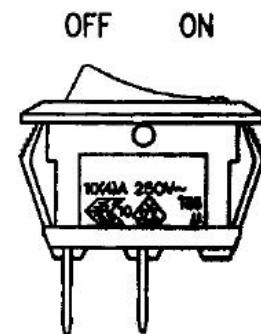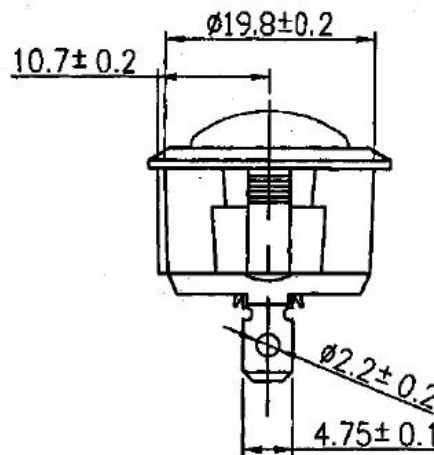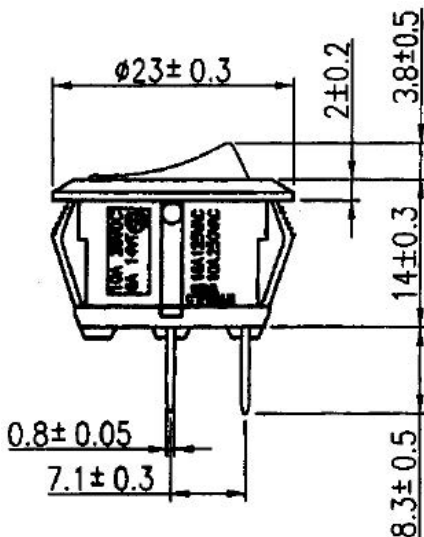

Unit: mm