

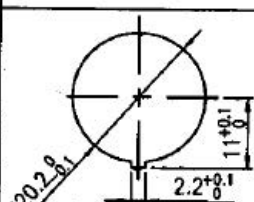
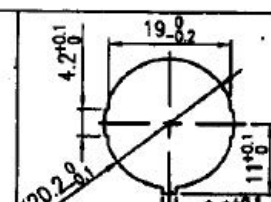
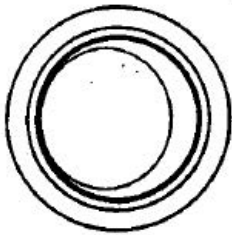
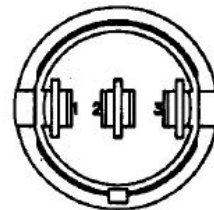
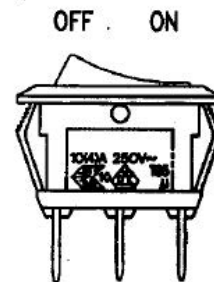
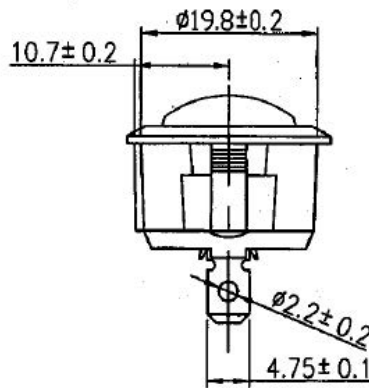


Rocker Switch - LED Red 12VDC, 16A/125 VAC (10A/250 VAC)

Rating	20A 12V DC	Mounting Hole	
Contact Resistance	50m ohm Max.	 <p>Panel Thickness 2.0~3.0 mm</p>	 <p>Panel Thickness 0.7~3.0 mm</p>
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		
Switch Function	3P SPST ON-OFF (Illuminated)		

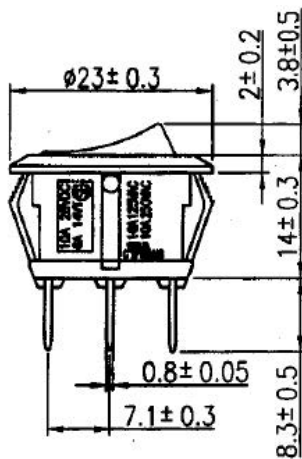

*Material
 Frame: Nylon#66,Black
 Actuator: Nylon#66,Black
 Lens: PC
 Terminal: Copper alloy,Silver plated

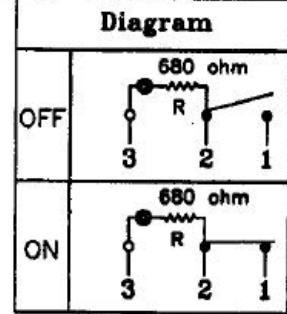

SCI NO.	Lens Color	LED Color
1823524	Red clear	Red
1823525	Green clear	Green

Unit: mm