

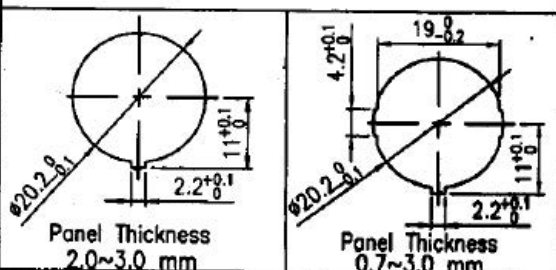
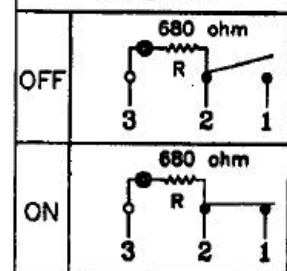
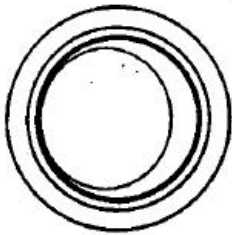
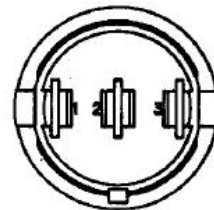
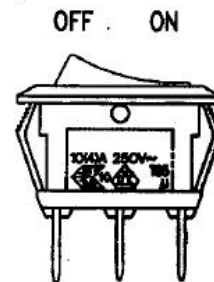


Rocker Switch - LED Green 12VDC, 16A/125 VAC (10A/250 VAC)

Rating	20A 12V DC	Mounting Hole	
Contact Resistance	50m ohm Max.		Diagram 
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		
Switch Function	3P SPST ON-OFF (Illuminated)		

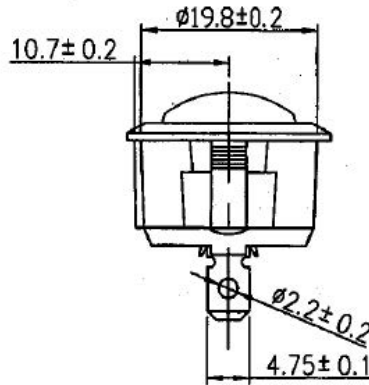

*Material
 Frame: Nylon#66,Black
 Actuator: Nylon#66,Black
 Lens: PC
 Terminal: Copper alloy,Silver plated

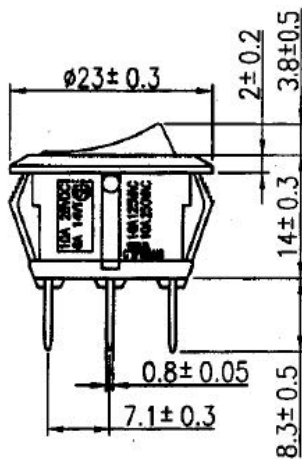

SCI NO.	Lens Color	LED Color
1823524	Red clear	Red
1823525	Green clear	Green

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.