

 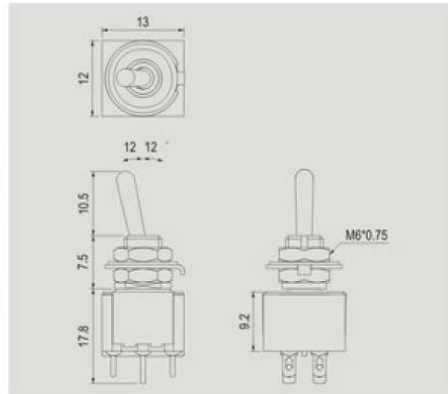


Mini Switch


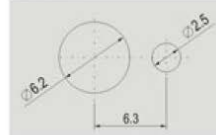


 
 

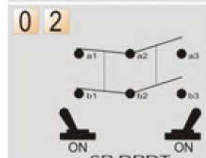
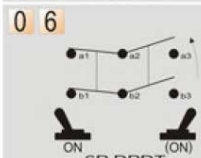

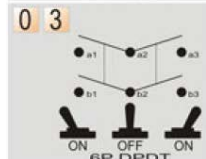

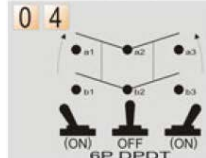


Rating
6A 125V AC 3A 250V AC
Contact resistant
50mΩ Max
Insulation resistant
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut out



FEATURES

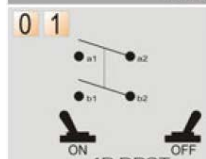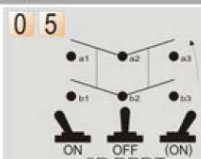- * MATERIAL: Blue alkyd or brown phenolic base (UL flame: 94V-0).
- * Contacts and Terminals are copper with silver alloy and silver plated.
- * Epoxy sealed for dust and moisture resistant.
- * Colorful handle covers and waterproof boot are optional for toggle type A.



FUNCTION		LEVER	TERMINAL
<p>0 1</p>  <p>ON OFF 4P DPST</p>	<p>0 5</p>  <p>ON OFF (ON) 6P DPDT</p>	<p>A Standard</p> 	<p>1  SO</p> <p>2  PC</p> <p>3  PC Angle(2.54)</p> <p>5  PC Angle(3.8)</p>
<p>0 2</p>  <p>ON ON 6P DPDT</p>	<p>0 6</p>  <p>ON OFF (ON) 6P DPDT</p>	<p>F Flat</p> 	
<p>0 3</p>  <p>ON OFF ON 6P DPDT</p>		<p>G Plastic</p> 	
<p>0 4</p>  <p>(ON) OFF (ON) 6P DPDT</p>			



Unit: mm