
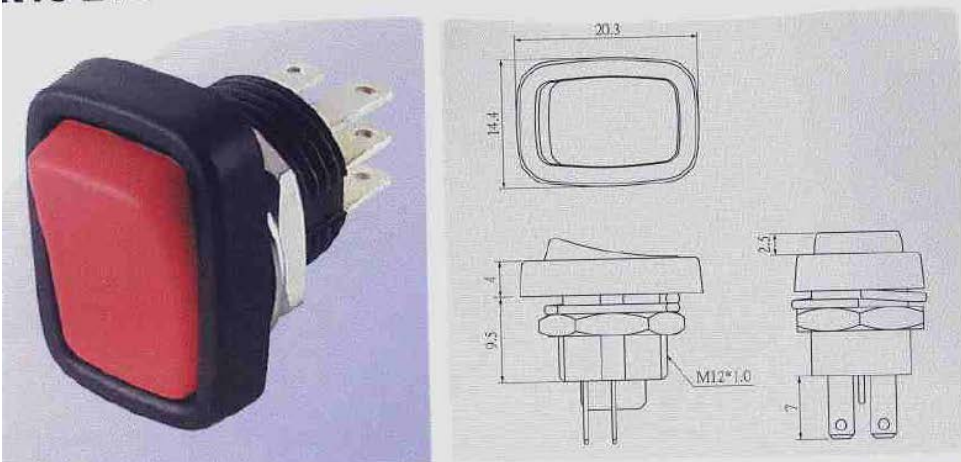


Rocker Switch (PRINT O / I)

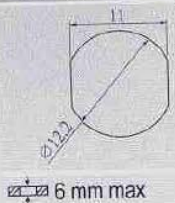


Rating
6A 125V AC 3A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out


FEATURES

- * MATERIAL: Frames are nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Specially for compact room design.

Protection Class: IP 30 Fireproof: 94V-2

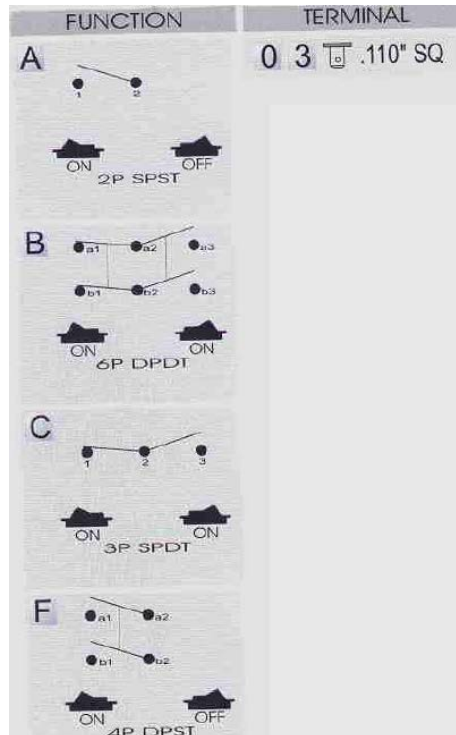

Unit: mm