


Datasheet

Item no. 1587649

V1_0817_01_en

Rocker Switch

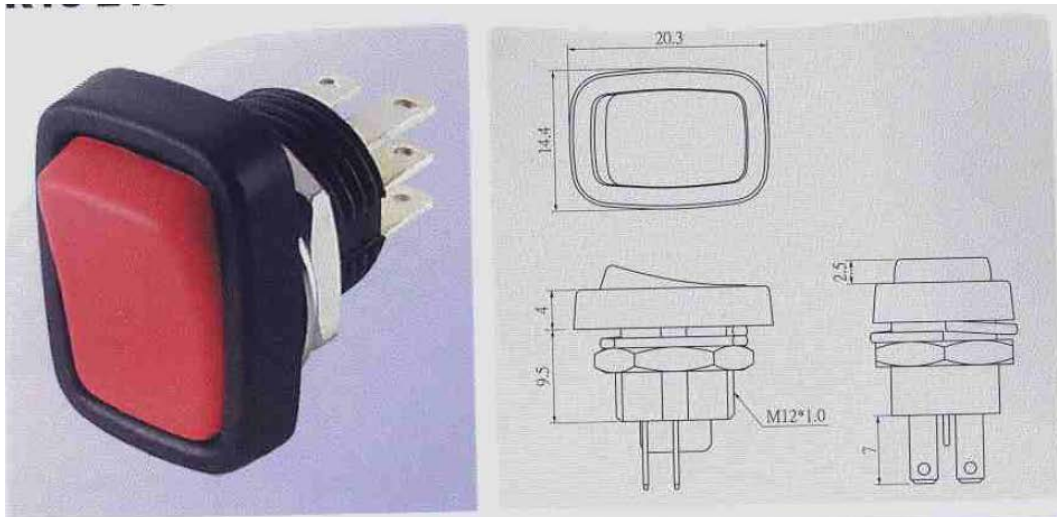


Rating
 6A 125V AC
 3A 250V AC

Contact resistance
 50mΩ Max

Insulation resistance
 DC 500V 100MΩ Min


Dielectric strength
 AC 1000V 1 minute

Cut-out

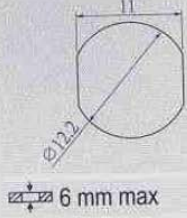

FEATURES

- * MATERIAL: Frames are nylon (UL flame: 94V-2). Terminals are silver plated brass.
- * Specially for compact room design.

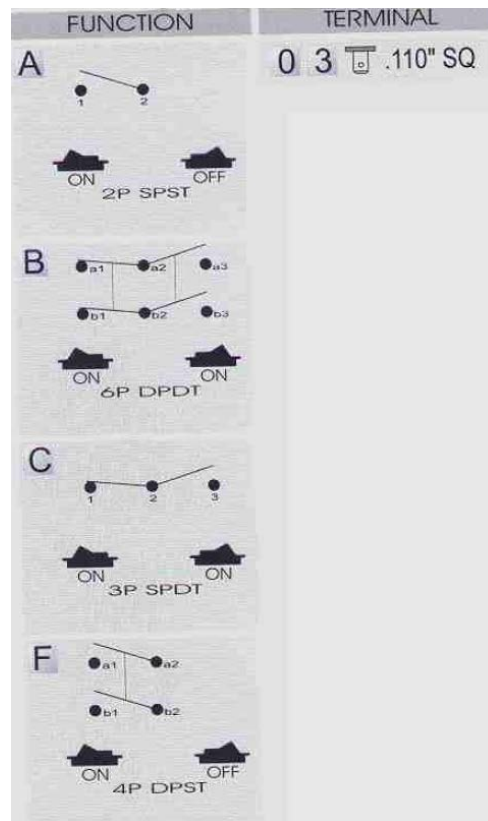

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.