


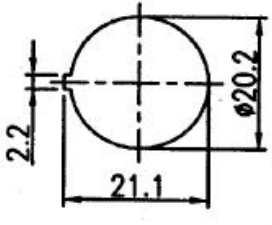
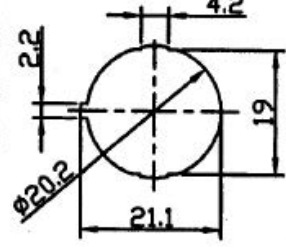


# Datasheet

Item no. 1587656







V1\_0817\_01\_en

## Rocker Switch

<b>Rating</b>	10(4)A 250V AC   16A 125V AC 10A 250V AC 	<b>Mounting Hole</b>	
<b>Contact Resistance</b>	50m ohm Max.		
<b>Insulation Resistance</b>	DC 500V 100M ohm Min.		
<b>Dielectric Strength</b>	AC 1500V 1 minute	Panel Thickness: 2.0~3.0	
<b>Operation Temperature</b>	-20°~85°	Panel Thickness: 0.7~3.0	
<b>Operation Force</b>	800g±200g		
<b>Switch Function</b>	4P DPST ON-OFF (Illuminated)		

\*Material  
 Frame: Nylon#66, Black  
 Lens: PC  
 Terminal: Copper alloy, Silver plated

### Diagram

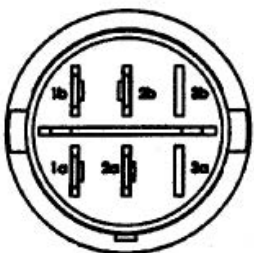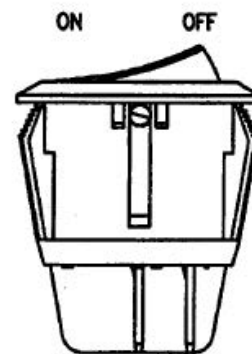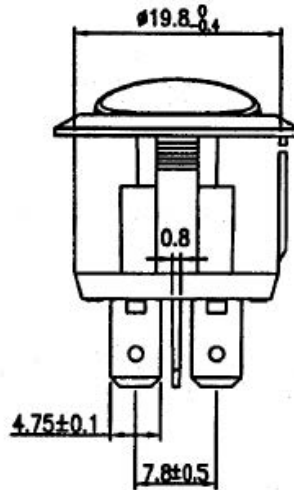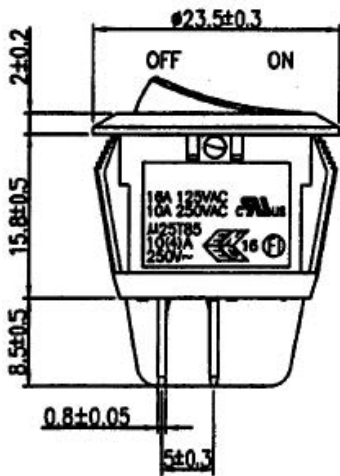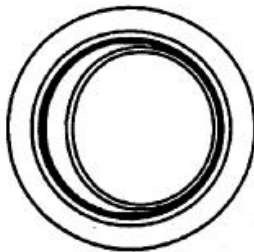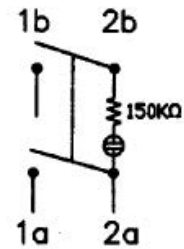

1822466	Red	Yellow clear
1821915	Red	Red clear
1821909	Green	Green clear
SCI NO.	Neon Light Color	Lens Color

Unit: mm