

 
 




Datasheet

Item no. 1587659

V1_0817_01_en

Rocker Switch

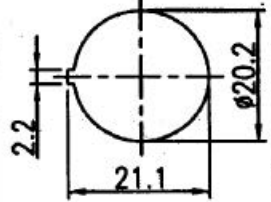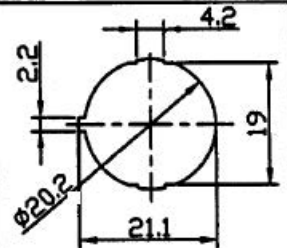Rating	10(4)A 250V AC   16A 125V AC 10A 250V AC  	Mounting Hole	
Contact Resistance	50m ohm Max.		
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute	Panel Thickness: 2.0~3.0	
Operation Temperature	-20°~85°	Panel Thickness: 0.7~3.0	
Operation Force	800g±200g		
Switch Function	6P DPDT ON-ON		







***Material**

Frame: Nylon#66, Black

Actuator: Nylon#66, Black

Terminal: Copper alloy, Silver plated

Diagram

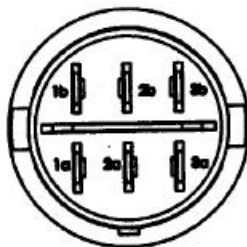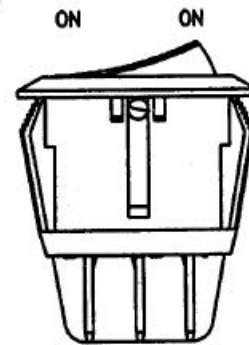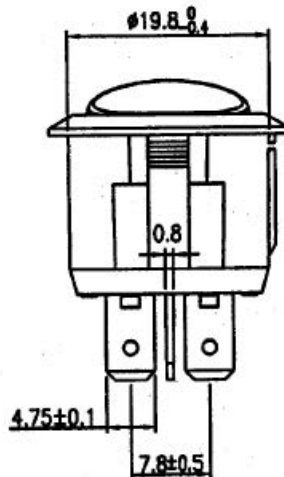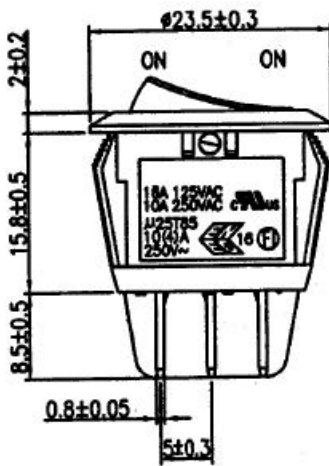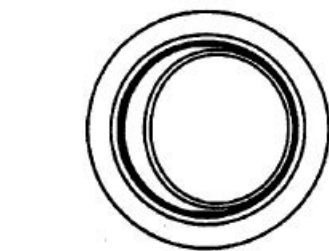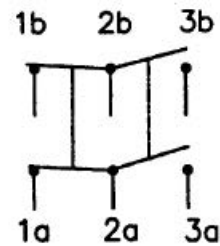

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.