
 

 
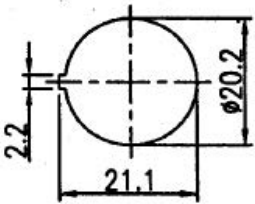
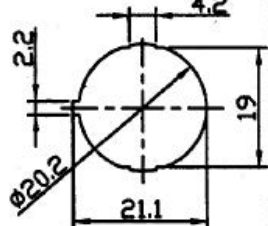


Rocker Switch, print I / 0 / II, quick terminal

Rating	10(4)A 250V AC   16A 125V AC  10A 250V AC 	Mounting Hole	
Contact Resistance	50m ohm Max.		
Insulation Resistance	DC 500V 100M ohm Min.	Panel Thickness: 2.0~3.0	
Dielectric Strength	AC 1500V 1 minute	Panel Thickness: 0.7~3.0	
Operation Temperature	-20°~85°		
Operation Force	800g±200g		
Switch Function	6P DPDT ON-OFF-ON		





***Material**

Frame: Nylon#66, Black

Actuator: Nylon#66, Black

Terminal: Copper alloy, Silver plated

Diagram

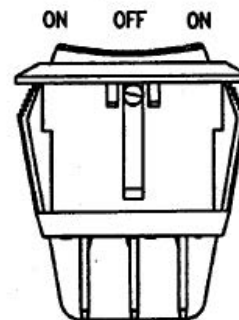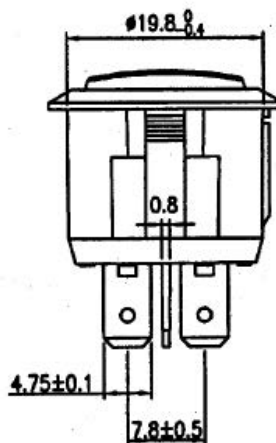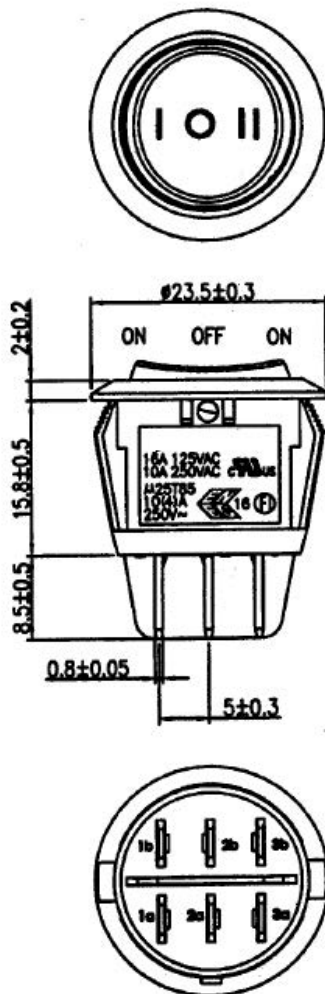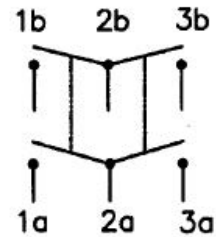

Unit: mm