



Toggle Switch

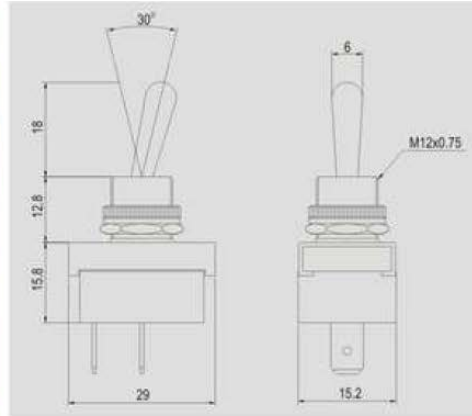

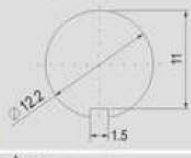


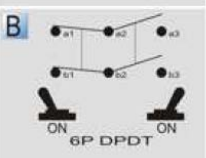

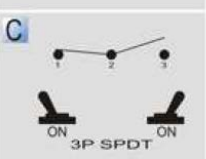


Rating
10A 125V AC 6A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1500V 1 minute
Cut-out


FEATURES

- * MATERIAL: Metal lever and bushing are nickel plated metal. Frame are metal plated. Plastic levers are ABS (UL flame: 94V-2).
- * Indicator plate is optional.
- * Waterproof boot is optional for metal lever.



FUNCTION		LEVER	TERMINAL
A		1 Plastic Lever	0 1  .250" SQ
B			0 5  SO
C		2 Metal Lever	
D			

Unit: mm