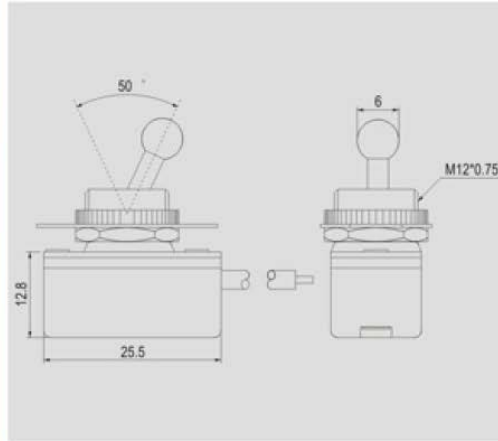
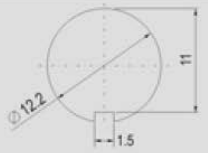


Toggle Switch



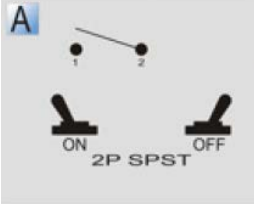

 
 

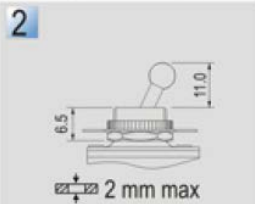

Rating
6A 125V AC 3A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out


FEATURES

- * MATERIAL: Metal lever and bushing are nickel plated metal. Frames are metal plated.
- * Phenolic base.
- * Indicator plate and waterproof boot are optional.



Unit: mm

FUNCTION	LEVER & MOUNTING SHAFT	TERMINAL
A  <p>ON OFF 2P SPST</p>	1  <p>4.3 mm max</p>	0 5  SO 0 8  SC 6-32UNC 1 1  WIRE
	2  <p>2 mm max</p>	
	3  <p>10.0 mm max</p>	

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.