
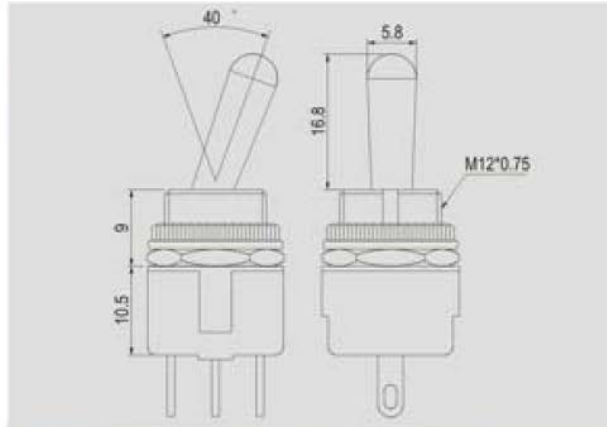



Toggle Switch (printing 125V/6A, 250V/3A)

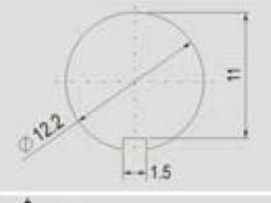

Rating
6A 125V AC 3A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out

4 mm max

FEATURES

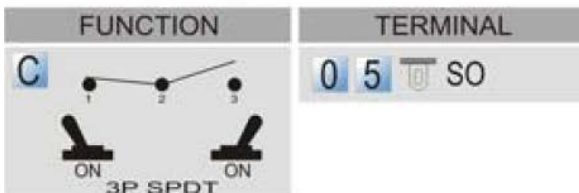- * MATERIAL: Metal lever and bushing are nickel plated metal. Frames are metal plated.
- * Phenolic base.
- * Indicator plate and waterproof boot are optional.
- * Application: Ceiling fan.



Unit: mm