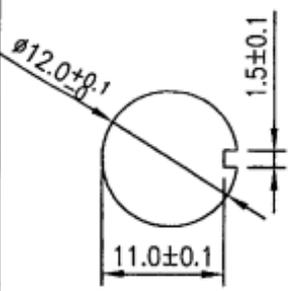
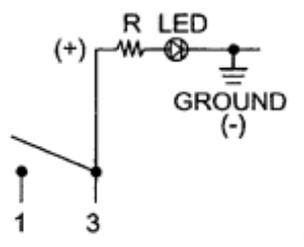



Datasheet

Item no.: 1587687




V1_0712_01_en

Toggle switch

Rating	20A 12V DC		
Contact Resistance	50m ohm Max.		
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		
Switch Function	3P SPST ON-OFF (LED)		
LED Color	Red		

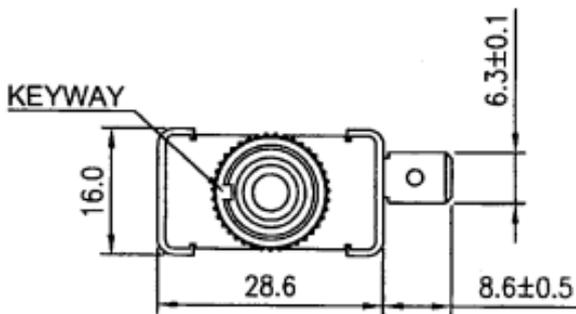

- 1 HEX NUT ASSY
- 1 SPRING WASHER ASSY
- 1 KNURL NUT ASSY

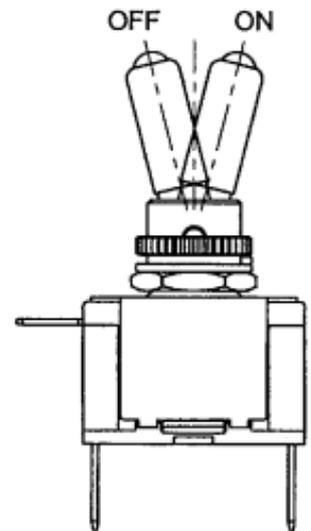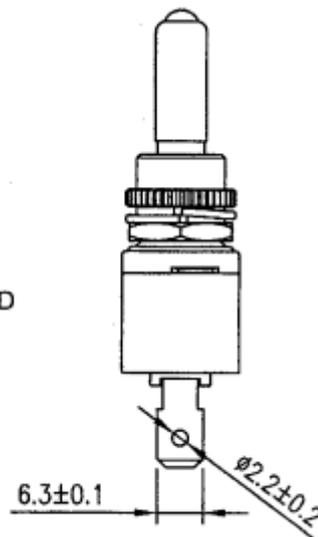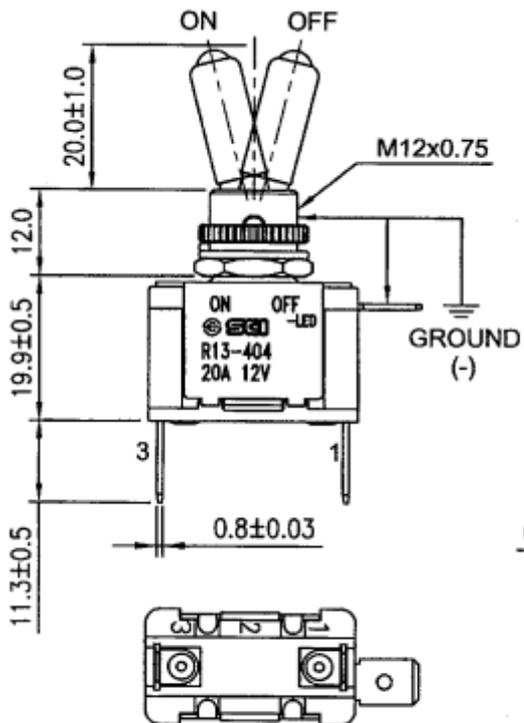

KEYWAY on "ON"

1 · Tolerances ± 0.3 Unless Otherwise Specified