






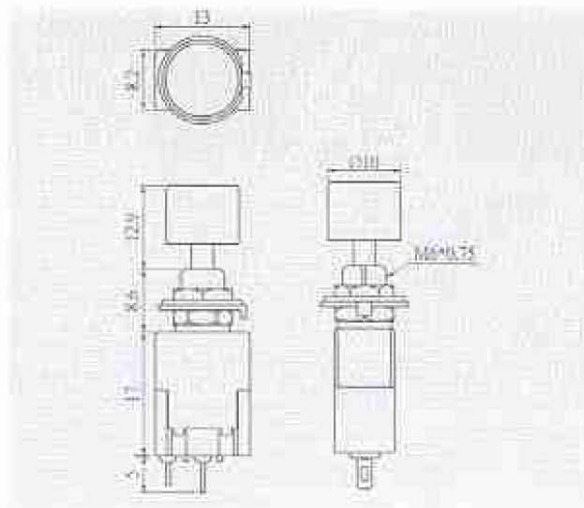



Mini Push-Button black switch, 3P ON-ON, 6A/125Vac, 3A/250Vac, standard toggle type(cfm)



Rating	6A 125V AC 3A 250V AC
Contact resistance	50mΩ Max
Insulation resistant	DC 500V 100MΩ Min
Dielectric strength	AC 1000V 1 minute
Cut-out	
	

FEATURES

- * MATERIAL: Alkyd base (UL flame: 94V-0) for high insulation. Stainless steel cover for high corrosion resistant.
- * Contacts and Terminals are copper with silver alloy and silver plated.
- * Epoxy sealed for dust and moisture resistant.

FUNCTION	BUTTON	TERMINAL
<p>0 1</p>  <p>ON OFF</p> <p>2P 1SP1T</p>	<p>A</p> 	<p>1  SO</p> <p>2  PC</p> <p>3  PC Angle(2.54)</p> <p>5  PC Angle(3.8)</p>
<p>0 2</p>  <p>ON ON</p> <p>3P 3P1T</p>		
<p>0 6</p>  <p>ON ON</p> <p>3P 3P1T (ON)</p>		

Fireproof: 94V-0
Protection Class: IP30

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.