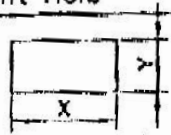
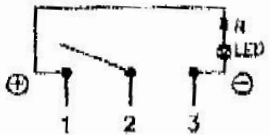


Datasheet


Item no. 1587861

V1_0817_01_en

Rocker switch, Off-On 3P SPST 21A 14VDC, 12V for yellow LED

Rating	21A 14VDC											
Contact R.	50m ohm Max.											
Insulation R.	DC 500V 100M ohm Min.	<table border="1"> <thead> <tr> <th>Thickness</th> <th>X</th> <th>Y</th> </tr> </thead> <tbody> <tr> <td>0.75-5mm</td> <td>36.8-0.1</td> <td>15.2-0.1</td> </tr> <tr> <td>0.03-0.2inch</td> <td>1.45"-0.004"</td> <td>.60"-0.004"</td> </tr> </tbody> </table>	Thickness	X	Y	0.75-5mm	36.8-0.1	15.2-0.1	0.03-0.2inch	1.45"-0.004"	.60"-0.004"	<p>12V R=680 ohm 24V R=1.5k ohm</p> <p>SPST 3P ON-OFF</p>
Thickness	X	Y										
0.75-5mm	36.8-0.1	15.2-0.1										
0.03-0.2inch	1.45"-0.004"	.60"-0.004"										
Operation Temp.	-20 ~ 85°C											
Operation force												
Safety approval												

Material: Case and bottom are nylon-66
actuator is nylon-66 with 33% glass
fiber, terminals are silver plated
copper, lens is PC.
Waterproof and dust proof to IP-66.
UV resistant.

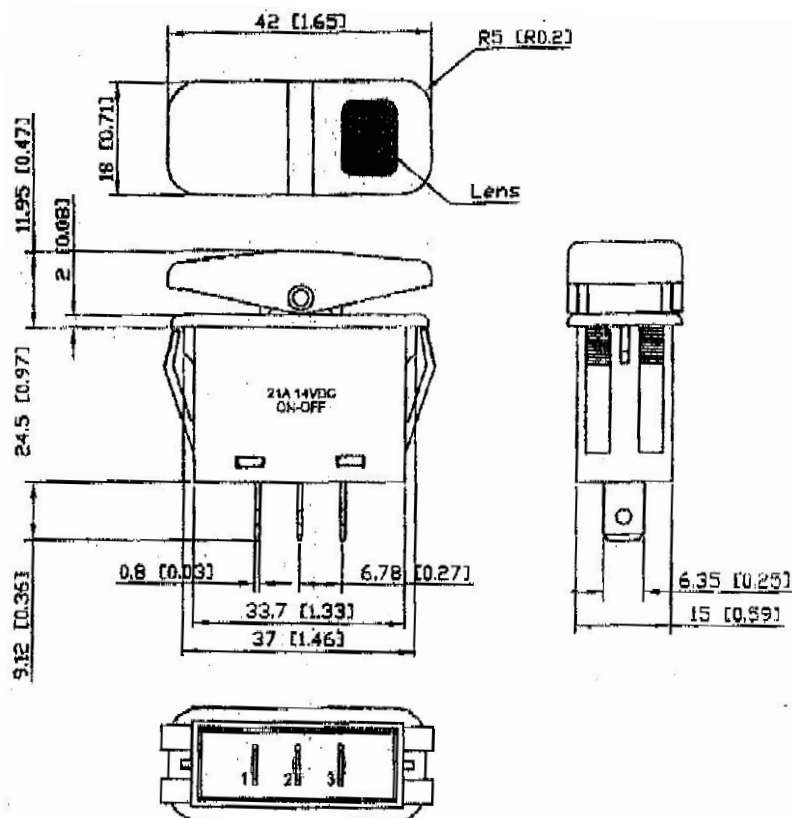

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.