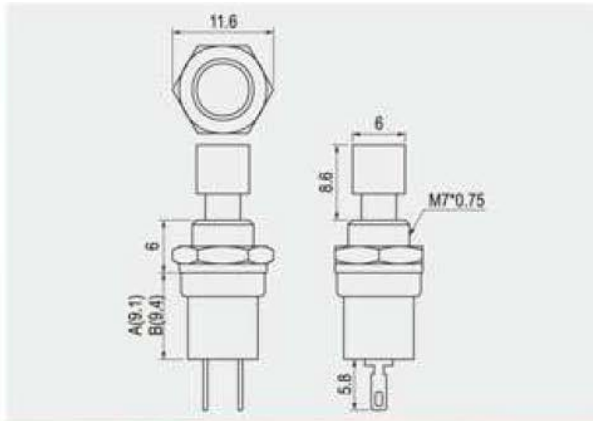


Datasheet

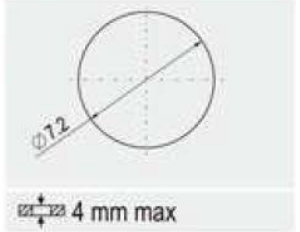
Item no. 1587878

V1_0817_01_en

Push Switch, Black Actuator

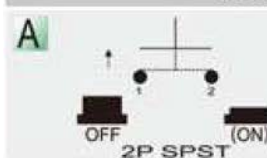
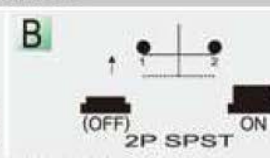
 




Rating
3A 125V AC 1.5A 250V AC
Contact resistance
50mΩ Max
Insulation resistance
DC 500V 100MΩ Min
Dielectric strength
AC 1000V 1 minute
Cut-out



FEATURES

- * MATERIAL: Actuator is PBT (UL Frames: 94V-0). Frame is nickel plated metal. Base is PBT (HB).
- * Actuator's size is optional.
- * Mounted by nut.

FUNCTION		BUTTON	TERMINAL
A  2P SPST OFF (ON)	B  2P SPST (OFF) ON * () =momentary	 Ø6*5.6	0 5  SO
		 L Ø10*8.5	

Unit: mm