



## Binding post, 10A 125V, blue

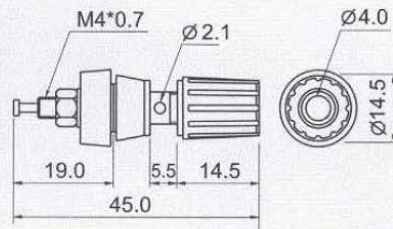

### FEATURES:

- Material:  
Insulation: nylon(UL flame: 94V-2) /PF.  
Metal: nickel plated brass.
- Ø4.0mm(0.160") banana socket with Ø 2.1mm (0.083") cross hole.

### CUT-OUT

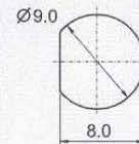

0.5~3.5mm

10A

DC500V 100MΩ

AC 1000V 1 minute

-10°C~+80°C

Unit: mm