
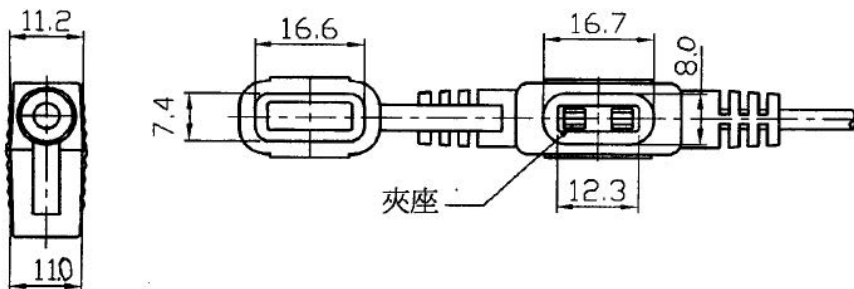


AST MINI BLADE FUSE without control LED

Rating	30A 32V
Contact R	50m ohm Max.
Insulation R	DC 500V 100M ohm Min.
Dielectric Strength	AC 1000V 1 minute
Operation Temperature	-20°C~85°C

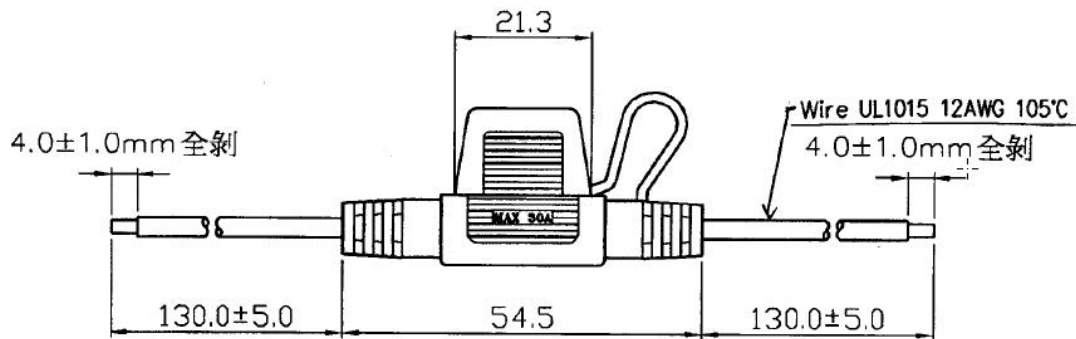

Unit: mm