 

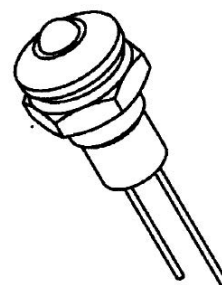


Indicator Light, 3mm Blue LED

LED Color	Lens Color	VF	Mounting Hole	Circuit Diagram
Blue	Blue diffused	3.4V	 Panel Thickness: 3.5 max	
IF	Viewing Angle	Med		
20mA	50°	700		
Insulation Resistance		DC500V 100M OHM Min		
Dielectric Strength		AC500V 1 minute		
Operation Temperature		(-)25°C-+85°C		

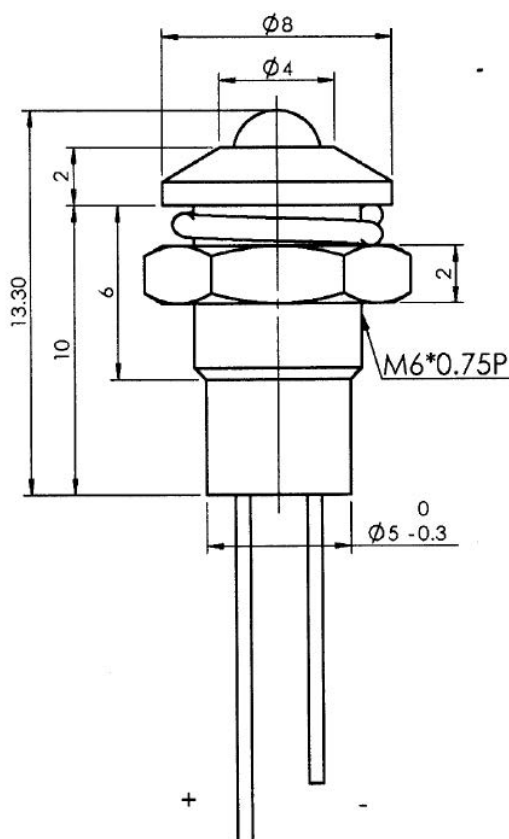

Unit: mm

Remark:

1. LED Type: Ø3mm
2. Unless Otherwise Specified All Tolerances To Be ±0.2
3. ROHS Compliant

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.