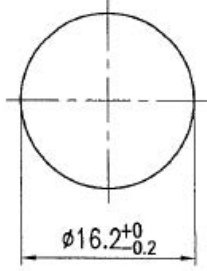



Datasheet

Item no. 1588039

V1_0817_01_en

Indicator 12V DC, Red

Rating	12V DC	<div style="text-align: center;"> Mounting Hole  <p>$\phi 16.2^{+0}_{-0.2}$</p> </div>
Insulation Resistance	DC 500V 100M ohm Min.	
Dielectric Strength	AC 1500V 1 minute.	
Operation Temperature	-20°C~80°C	

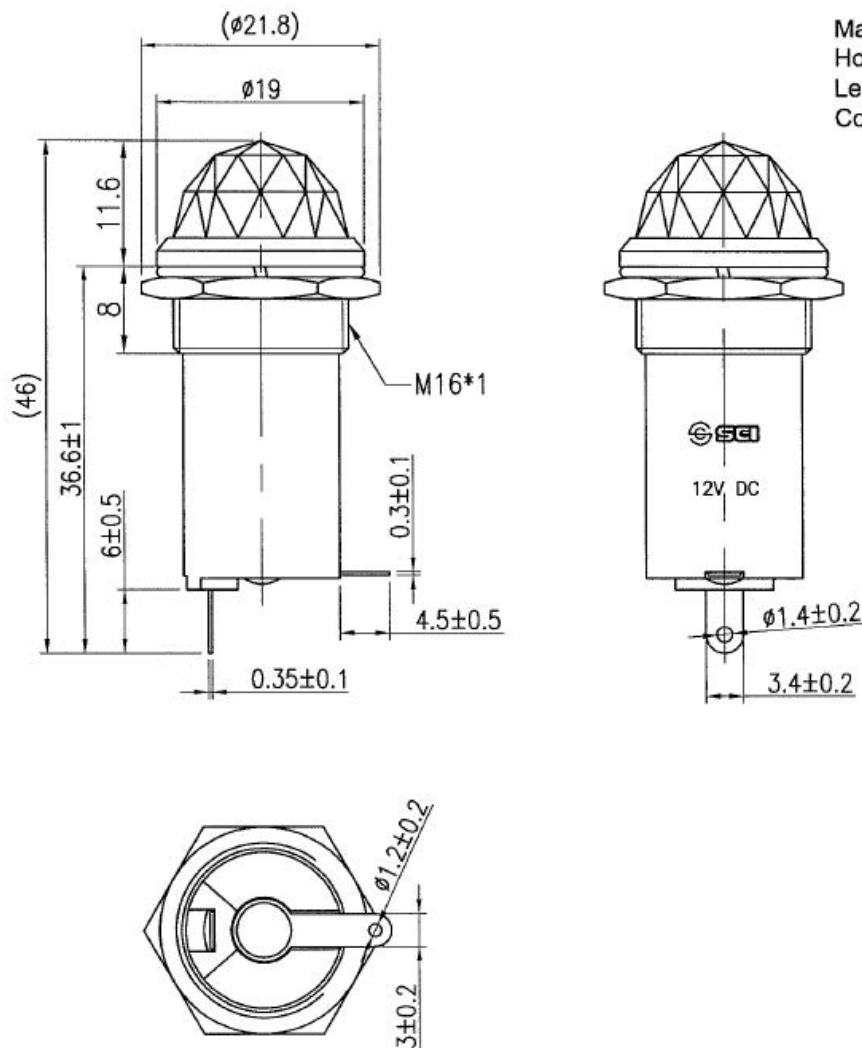

Tolerance Unless Otherwise Specified ±0.3

Unit: mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.