
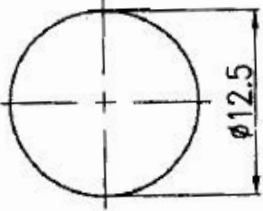
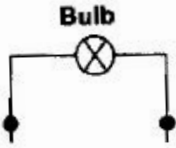


Indicator, Blue

| Rating | 12V DC | Mounting Hole | Circuit Diagram |
|-----------------------|----------------------|------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------|
| Insulation Resistance | DC 500V 100M ohm Min |  |  <p>12VDC 3/4W</p> |
| Dielectric Strength | AC 1500V 1 minute | | |
| Operation Temperature | -20°C~85°C | | |
| | | | |

Material:
 Frame: blue, PC
 Base: black, nylon 66+33%GF

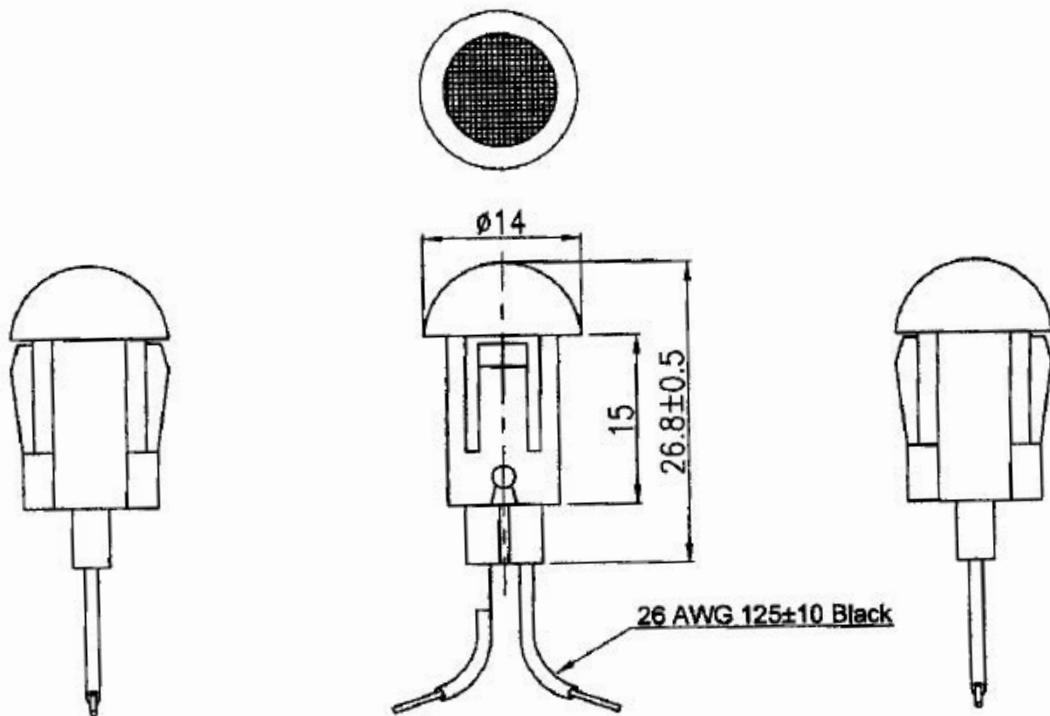

Tolerances Unless Otherwise Specified ± 0.3

Unit mm

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.