


Datasheet

Item no. 1588960, 1588961, 1589158, 1588906, 1588973, 1588958, 1588959, 1589155, 1588975, 1589156, 1588976, 1588956, 1589031, 1589162, 1589030, 1589035, 1589161, 1588974, 1588978, 1589160, 1588907, 1588905, 1589163, 1589159, 1589039, 1589034, 1588962, 1588957, 1588977, 1589038, 1589033, 1589037, 1589157, 1589036, 1589032

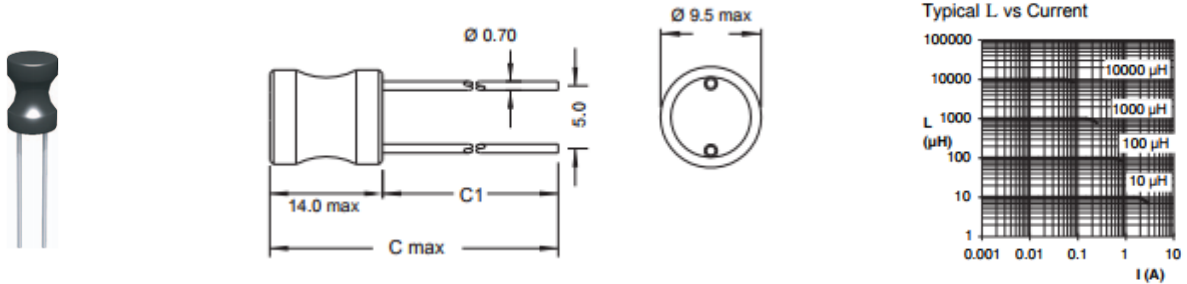

| Part No | Inductance L (μH) | f _L (MHz) | Tol ± (%) | Q (min) | f _Q (MHz) | SRF min (MHz) | DCR max (Ω) | Rated DC Current (mA) |
|-------------------|-------------------|----------------------|-----------|---------|----------------------|---------------|-------------|-----------------------|
| TC-09P-101K-50203 | 100 | 0.02 | 5,10 | 40 | 0.796 | 5 | 0.3 | 790 |
| TC-09P-151J-50203 | 150 | 0.02 | 5,10 | 50 | 0.796 | 4 | 0.4 | 650 |
| TC-09P-151K-51203 | 150 | 0.02 | 5,10 | 50 | 0.796 | 4 | 0.4 | 650 |
| TC-09P-222J-51203 | 2200 | 0.02 | 5,10 | 70 | 0.252 | 1 | 7 | 180 |
| TC-09P-330K-51203 | 33 | 0.02 | 5,10 | 30 | 2.52 | 9 | 0.08 | 1350 |
| TC-09P-332J-51203 | 3300 | 0.02 | 5,10 | 70 | 0.252 | 0.8 | 9 | 150 |
| TC-09P-470K-50203 | 47 | 0.02 | 5,10 | 30 | 2.52 | 7 | 0.1 | 1100 |
| TC-09P-471K-50203 | 470 | 0.02 | 5,10 | 35 | 0.796 | 2.3 | 1.3 | 420 |
| TC-09P-822J-50203 | 8200 | 0.02 | 5,10 | 70 | 0.252 | 0.5 | 20 | 100 |
| TC-09P-821K-50203 | 820 | 0.02 | 5,10 | 35 | 0.796 | 1.7 | 2.2 | 310 |
| TC-09P-103J-50203 | 10000 | 0.02 | 5,10 | 70 | 0.079 | 0.41 | 35 | 90 |
| TC-09P-100K-50203 | 10 | 0.02 | 5,10 | 70 | 2.52 | 18 | 0.03 | 2400 |
| TC-09P-681K-50203 | 680 | 0.02 | 5,10 | 35 | 0.796 | 1.9 | 1.9 | 350 |
| TC-09P-562J-50203 | 5600 | 0.02 | 5,10 | 70 | 0.252 | 0.63 | 15 | 120 |
| TC-09P-561K-50203 | 560 | 0.02 | 5,10 | 35 | 0.796 | 2 | 1.5 | 400 |
| TC-09P-472J-50203 | 4700 | 0.02 | 5,10 | 70 | 0.252 | 0.65 | 11.5 | 130 |
| TC-09P-392J-50203 | 3900 | 0.02 | 5,10 | 70 | 0.252 | 0.75 | 10 | 140 |
| TC-09P-391K-50203 | 390 | 0.02 | 5,10 | 35 | 0.796 | 2.5 | 1.1 | 460 |
| TC-09P-333J-50203 | 33000 | 0.02 | 5,10 | 70 | 0.079 | 0.26 | 75 | 50 |
| TC-09P-332J-50203 | 3300 | 0.02 | 5,10 | 70 | 0.252 | 0.8 | 9 | 150 |
| TC-09P-331K-50203 | 330 | 0.02 | 5,10 | 35 | 0.796 | 2.7 | 1 | 500 |
| TC-09P-330K-50203 | 33 | 0.02 | 5,10 | 30 | 2.52 | 9 | 0.08 | 1350 |
| TC-09P-273J-50203 | 27000 | 0.02 | 5,10 | 70 | 0.079 | 0.29 | 70 | 55 |
| TC-09P-272J-50203 | 2700 | 0.02 | 5,10 | 70 | 0.252 | 0.9 | 8 | 170 |
| TC-09P-223J-50203 | 22000 | 0.02 | 5,10 | 70 | 0.079 | 0.3 | 58 | 60 |
| TC-09P-222J-50203 | 2200 | 0.02 | 5,10 | 70 | 0.252 | 1 | 7 | 180 |
| TC-09P-221K-51203 | 220 | 0.02 | 5,10 | 30 | 0.796 | 3.3 | 0.5 | 530 |
| TC-09P-220K-51203 | 22 | 0.02 | 5,10 | 40 | 2.52 | 12 | 0.05 | 1650 |
| TC-09P-183J-50203 | 18000 | 0.02 | 5,10 | 70 | 0.079 | 0.34 | 50 | 65 |
| TC-09P-153J-50203 | 15000 | 0.02 | 5,10 | 70 | 0.079 | 0.35 | 45 | 70 |
| TC-09P-152J-50203 | 1500 | 0.02 | 5,10 | 70 | 0.252 | 1.2 | 5.1 | 220 |
| TC-09P-123J-50203 | 12000 | 0.02 | 5,10 | 70 | 0.079 | 0.38 | 40 | 80 |
| TC-09P-122J-50203 | 1200 | 0.02 | 5,10 | 70 | 0.252 | 1.4 | 3 | 250 |
| TC-09P-682J-50203 | 6800 | 0.02 | 5,10 | 70 | 0.252 | 0.57 | 17 | 110 |
| TC-09P-102J-50203 | 1000 | 0.02 | 5,10 | 70 | 0.252 | 1.6 | 2.6 | 280 |

Material: Ferrite