


# Datasheet

Item no. 1588960, 1588961, 1589158, 1588906, 1588973, 1588958, 1588959, 1589155, 1588975, 1589156, 1588976, 1588956, 1589031, 1589162, 1589030, 1589035, 1589161, 1588974, 1588978, 1589160, 1588907, 1588905, 1589163, 1589159, 1589039, 1589034, 1588962, 1588957, 1588977, 1589038, 1589033, 1589037, 1589157, 1589036, 1589032

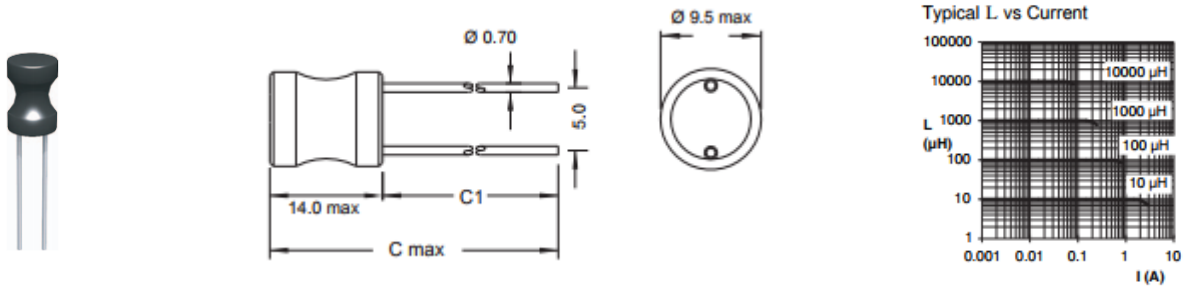

Part No	Inductance L (μH)	f <sub>L</sub> (MHz)	Tol ± (%)	Q (min)	f <sub>Q</sub> (MHz)	SRF min (MHz)	DCR max (Ω)	Rated DC Current (mA)
TC-09P-101K-50203	100	0.02	5,10	40	0.796	5	0.3	790
TC-09P-151J-50203	150	0.02	5,10	50	0.796	4	0.4	650
TC-09P-151K-51203	150	0.02	5,10	50	0.796	4	0.4	650
TC-09P-222J-51203	2200	0.02	5,10	70	0.252	1	7	180
TC-09P-330K-51203	33	0.02	5,10	30	2.52	9	0.08	1350
TC-09P-332J-51203	3300	0.02	5,10	70	0.252	0.8	9	150
TC-09P-470K-50203	47	0.02	5,10	30	2.52	7	0.1	1100
TC-09P-471K-50203	470	0.02	5,10	35	0.796	2.3	1.3	420
TC-09P-822J-50203	8200	0.02	5,10	70	0.252	0.5	20	100
TC-09P-821K-50203	820	0.02	5,10	35	0.796	1.7	2.2	310
TC-09P-103J-50203	10000	0.02	5,10	70	0.079	0.41	35	90
TC-09P-100K-50203	10	0.02	5,10	70	2.52	18	0.03	2400
TC-09P-681K-50203	680	0.02	5,10	35	0.796	1.9	1.9	350
TC-09P-562J-50203	5600	0.02	5,10	70	0.252	0.63	15	120
TC-09P-561K-50203	560	0.02	5,10	35	0.796	2	1.5	400
TC-09P-472J-50203	4700	0.02	5,10	70	0.252	0.65	11.5	130
TC-09P-392J-50203	3900	0.02	5,10	70	0.252	0.75	10	140
TC-09P-391K-50203	390	0.02	5,10	35	0.796	2.5	1.1	460
TC-09P-333J-50203	33000	0.02	5,10	70	0.079	0.26	75	50
TC-09P-332J-50203	3300	0.02	5,10	70	0.252	0.8	9	150
TC-09P-331K-50203	330	0.02	5,10	35	0.796	2.7	1	500
TC-09P-330K-50203	33	0.02	5,10	30	2.52	9	0.08	1350
TC-09P-273J-50203	27000	0.02	5,10	70	0.079	0.29	70	55
TC-09P-272J-50203	2700	0.02	5,10	70	0.252	0.9	8	170
TC-09P-223J-50203	22000	0.02	5,10	70	0.079	0.3	58	60
TC-09P-222J-50203	2200	0.02	5,10	70	0.252	1	7	180
TC-09P-221K-51203	220	0.02	5,10	30	0.796	3.3	0.5	530
TC-09P-220K-51203	22	0.02	5,10	40	2.52	12	0.05	1650
TC-09P-183J-50203	18000	0.02	5,10	70	0.079	0.34	50	65
TC-09P-153J-50203	15000	0.02	5,10	70	0.079	0.35	45	70
TC-09P-152J-50203	1500	0.02	5,10	70	0.252	1.2	5.1	220
TC-09P-123J-50203	12000	0.02	5,10	70	0.079	0.38	40	80
TC-09P-122J-50203	1200	0.02	5,10	70	0.252	1.4	3	250
TC-09P-682J-50203	6800	0.02	5,10	70	0.252	0.57	17	110
TC-09P-102J-50203	1000	0.02	5,10	70	0.252	1.6	2.6	280

Material: Ferrite