


Datasheet

Item no. 1589242, 1589106, 1589245, 1589249, 1589109, 1589250, 1589243, 1589246, 1589107, 1589108, 1589247, 1589244, 1589248, 1589110

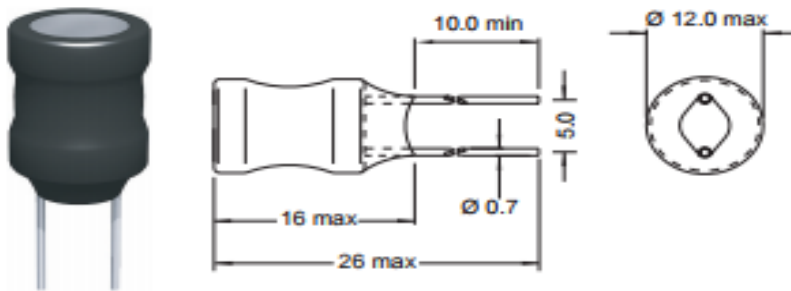

Part No	Inductance L (mH)	f_L (MHz)	Tol \pm (%)	Q (min)	f_Q (MHz)	SRF min (MHz)	DCR max (Ω)	Rated DC Current (mA)
TC-11P-100K-50203	0.01	0.02	10	70	2.52	20	0.035	3500
TC-11P-101K-50203	0.1	0.02	10	40	0.079	3.4	0.2	950
TC-11P-103K-50203	10	0.02	5,10	50	0.079	0.35	23	110
TC-11P-104K-50203	100	0.02	5,10	50	0.025	0.11	155	40
TC-11P-153K-50203	15	0.02	5,10	50	0.079	0.29	28	90
TC-11P-154K-50203	150	0.02	5,10	50	0.025	0.08	205	35
TC-11P-221K-50203	0.22	0.02	10	40	0.079	2.3	0.32	700
TC-11P-223K-50203	22	0.02	5,10	50	0.079	0.25	39	70
TC-11P-331K-50203	0.33	0.02	10	30	0.079	1.88	0.6	590
TC-11P-332K-50203	3.3	0.02	5,10	47	0.252	0.6	3.7	190
TC-11P-333K-50203	33	0.02	5,10	50	0.079	0.2	56	65
TC-11P-471K-50203	0.47	0.02	10	25	0.079	1.55	0.7	470
TC-11P-473K-50203	47	0.02	5,10	50	0.079	0.18	73	55
TC-11P-683K-50203	68	0.02	5,10	50	0.079	0.13	120	50

Material: Ferrite

Typical L vs Current

