



# Datasheet

Item no. 1589274, 1589276, 1589004, 1589275, 1589122, 1589123

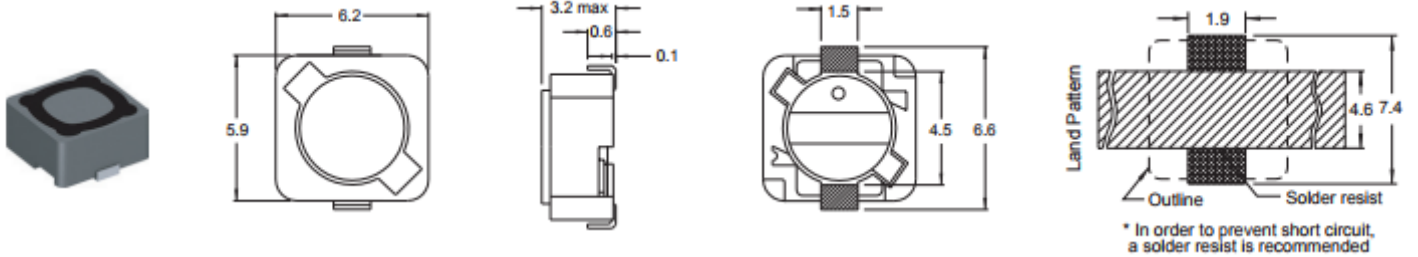

Part No	Inductance L (μH)	f <sub>L</sub> (kHz)	Tol ± (%)	DCR max (Ω)	Rated DC Current I <sub>SAT</sub> (A)
TC-PIS2408-100M203	10	1	20	0.15	1.1
TC-PIS2408-101M203	100	1	20	1.39	0.34
TC-PIS2408-150M203	15	1	20	0.23	0.9
TC-PIS2408-270M203	27	1	20	0.38	0.66
TC-PIS2408-271M203	270	1	20	4.38	0.22
TC-PIS2408-331M203	330	1	20	4.94	0.19

Typical L vs Frequency(f)

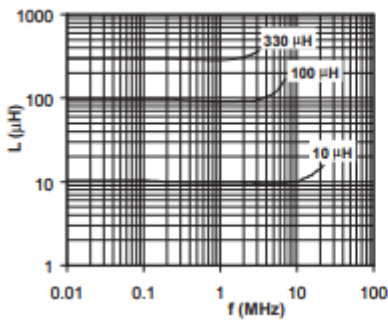

Typical L vs Current

