


# Datasheet

Item no. 1589133, 1589015, 1589302, 1589301, 1589134

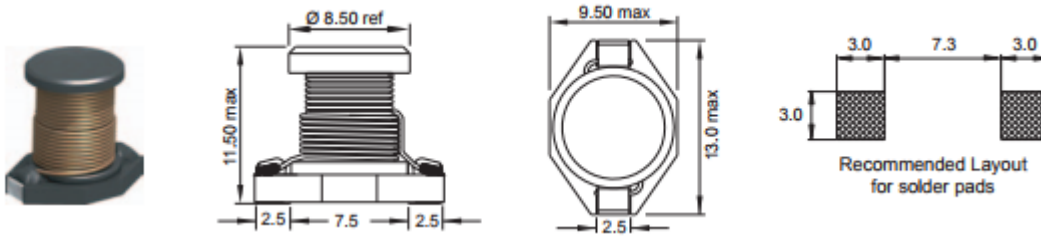

Part No	Inductance L (μH)	f <sub>L</sub> (MHz)	Tol ± (%)	SRF min (MHz)	DCR max (Ω)	Rated DC Current (A)	
						I <sub>SAT</sub>	I <sub>ΔT = 40°C</sub>
TC-PISN-101M-04203	100	0.1	20	5	0.21	2.6	1.5
TC-PISN-150M-04203	15	0.1	20	15	0.035	7.1	4.2
TC-PISN-221M-04203	220	0.1	20	2.8	0.39	1.7	1.1
TC-PISN-330M-04203	33	0.1	20	11	0.065	4.3	3.1
TC-PISN-681M-04203	680	0.1	20	1.5	1.2	1.05	0.5

Material: Ferrite

Typical L vs Frequency(f)

