


Datasheet

Item no. 1589289, 1589292, 1589128, 1589008, 1589286, 1589130, 1589287, 1589009, 1589007, 1589290, 1589288, 1589291, 1589129

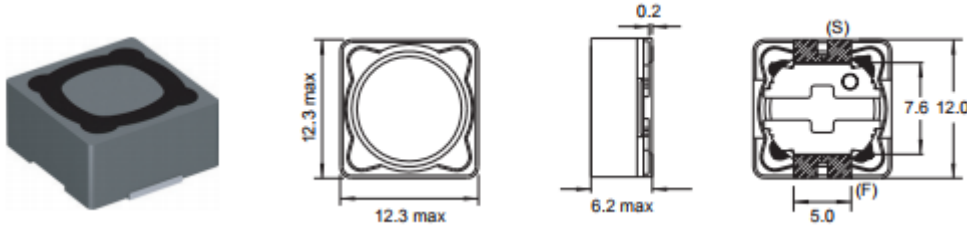

Part No	Inductance L (μH)	f_L (kHz)	Tol ± (%)	DCR max (mΩ)	Rated DC Current I (A)
TC-PIS4720-101M203	100	1	20	160	1.3
TC-PIS4720-102M203	1000	1	20	1530	0.4
TC-PIS4720-150M203	15	1	20	30	3.3
TC-PIS4720-151M203	150	1	20	230	1
TC-PIS4720-220M203	22	1	20	36	2.8
TC-PIS4720-221M203	220	1	20	400	0.8
TC-PIS4720-270M203	27	1	20	51	2.3
TC-PIS4720-271M203	270	1	20	460	0.75
TC-PIS4720-330M203	33	1	20	57	2.1
TC-PIS4720-331M203	330	1	20	510	0.68
TC-PIS4720-470M203	47	1	20	75	1.8
TC-PIS4720-471M203	470	1	20	770	0.58
TC-PIS4720-680M203	68	1	20	120	1.5

Material: Ferrite

