


# Datasheet

Item no. 1589460

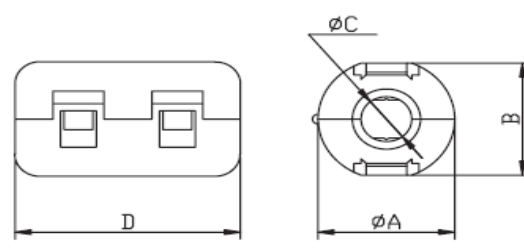

MATERIAL		RF75	
DIMENSIONS			
A	13.0 ± 0.50 (mm)		
B	12.5 ± 0.50 (mm)		
C	5.00 ± 0.30 (mm)		
D	25.2 ± 0.80 (mm)		
ELECTRIC CHARACTER		25 MHz	100 MHz
		≥ 60 R	≥ 120 R
WINDING		2 UEW Φ 0.65 × 120 mm 1/2Ts	
TEST CONDITIONS		temperature	25 °C
		humidity	75 %

Impedance curve:

