



# Datasheet

Item no. 1589461

MATERIAL		RF75	
DIMENSIONS			
A	17.5 ± 1.0 (mm)		
B	19.5 ± 1.0 (mm)		
C	6.50 ± 0.4 (mm)		
D	32.5 ± 1.0 (mm)		
			
ELECTRIC CHARACTER		25 MHz	100 MHz
		≥ 120	≥ 200
WINDING		2 UEW Φ0.65 × 120 mm 1/2Ts	
TEST CONDITIONS		temperature	25 °C
		humidity	75 %

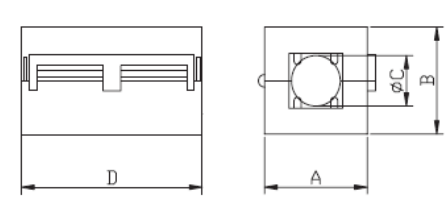