

Datasheet

Item no. 1589494




DESCRIPTION:

- ZINC ALLOY DIE CAST HOUSING AND CYLINDER WITH DUST PROOF SHUTTER.
- 5-DISC TUMBLER CYLINDER.
- TWO DURABLE NICKEL PLATED SOLID BRASS DOUBLE BITTED KEYS GOING IN EITHER WAY FOR EASY OPERATION.
- TERMINALS AND CONTACTS WITH SILVER PLATED.
- HEX NUT MOUNTED.
- TWO TERMINALS.

MATERIALS:

LOCK	: ZINC ALLOY WITH STAINLESS STEEL CAP .
KEYS	: TWO NICKEL PLATED BRASSKEYS WITH CODE NUMBER.
SWITCH HOUSING	: 6/6 NYLON (UL 94V-0).
CONTACTS & TERMINALS	: COPPER ALLOY, SILVER PLATED.
HOUNTING NUT	: STEEL.NICKEL PLATED.

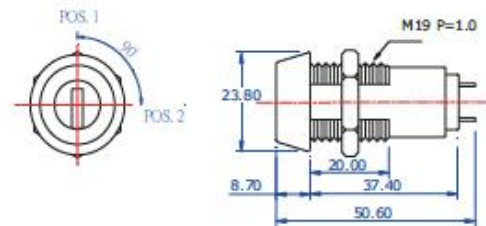

Hold size



ELECTRICAL SPECIFICATION:

CONTACT RATING:	: 4A 125VAC/28VDC 2A 250VAC
CONTACT RESISTANCE:	: BELOW 50 MILLION OHMS.
INSULATION RESISTANCE:	: 10 ⁹ OHMS MIN.
DIELECTRIC STRENGTH:	: 1000V RMS MIN. SEA LEVEL.
ELECTRICAL LIFE:	: 6,000 MAKE-AND-BREAK CYCLES AT. FULL LOAD.

TERMINAL

