


# Datasheet

Item no. TC-CDS16

Decode switch hexadecimal 16 position print 25 mA 24 Vdc

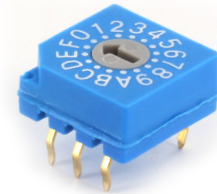

## Specification:

Terminal	print
Kind	rotary decode switch
Illumination	none
Operating Current	≤ 25 mA
Operating Temperature	-25 °C - 70 °C
Input Voltage	≤ 24 Vdc
Colour	blue
Operating Life in Switching Cycles	≥ 10000 (at nominal load)
Soldering Heat	≤ 260 °C for 5 s
Material (Terminal)	copper alloy, gold plated
Pitch	2.54 mm
Torque Value	4.9 Ncm
Transmission Voltage	50 Vdc
Transmission Current	100 mA
Dielectric Strength	250 Vac
Insulation Resistance (Min.)	1 GΩ (100 Vdc)
Contact Resistance (Max.)	100 mΩ

