


## Data Sheet

### Cable tie

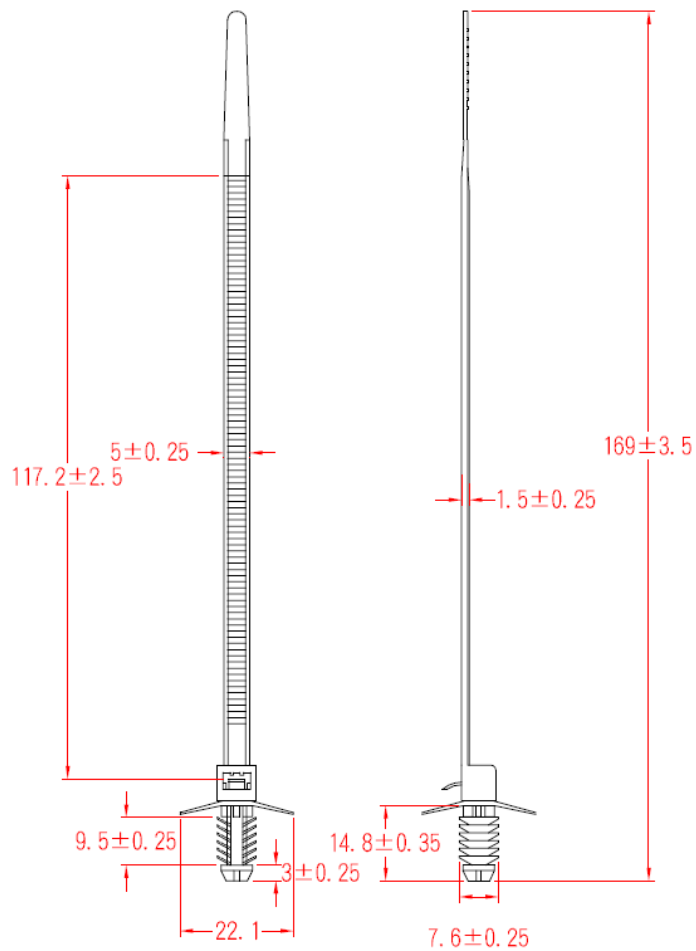

To fit 6.8mm hole  
Drill Depth 15mm

## Data Sheet

---

- Bore diameter: 6.8 mm

<b>Colour</b>	Black
<b>Cable tie length</b>	169 mm
<b>Cable tie width</b>	5 mm
<b>Features</b>	Spring toggle and disc
<b>Gearing</b>	Outside
<b>Max. temperature</b>	+85 °C
<b>Min. temperature</b>	-40 °C
<b>Halogen-free</b>	Yes
<b>Material</b>	Polyamide 6.6
<b>Content</b>	1 pc(s)
<b>Minimum holding force</b>	178 N
<b>Max. sheet thickness</b>	15 mm
<b>Max. bundle diameter</b>	36 mm
<b>RoHS-compliant</b>	Yes