


DATASHEET

Adjustable Cable Clamp

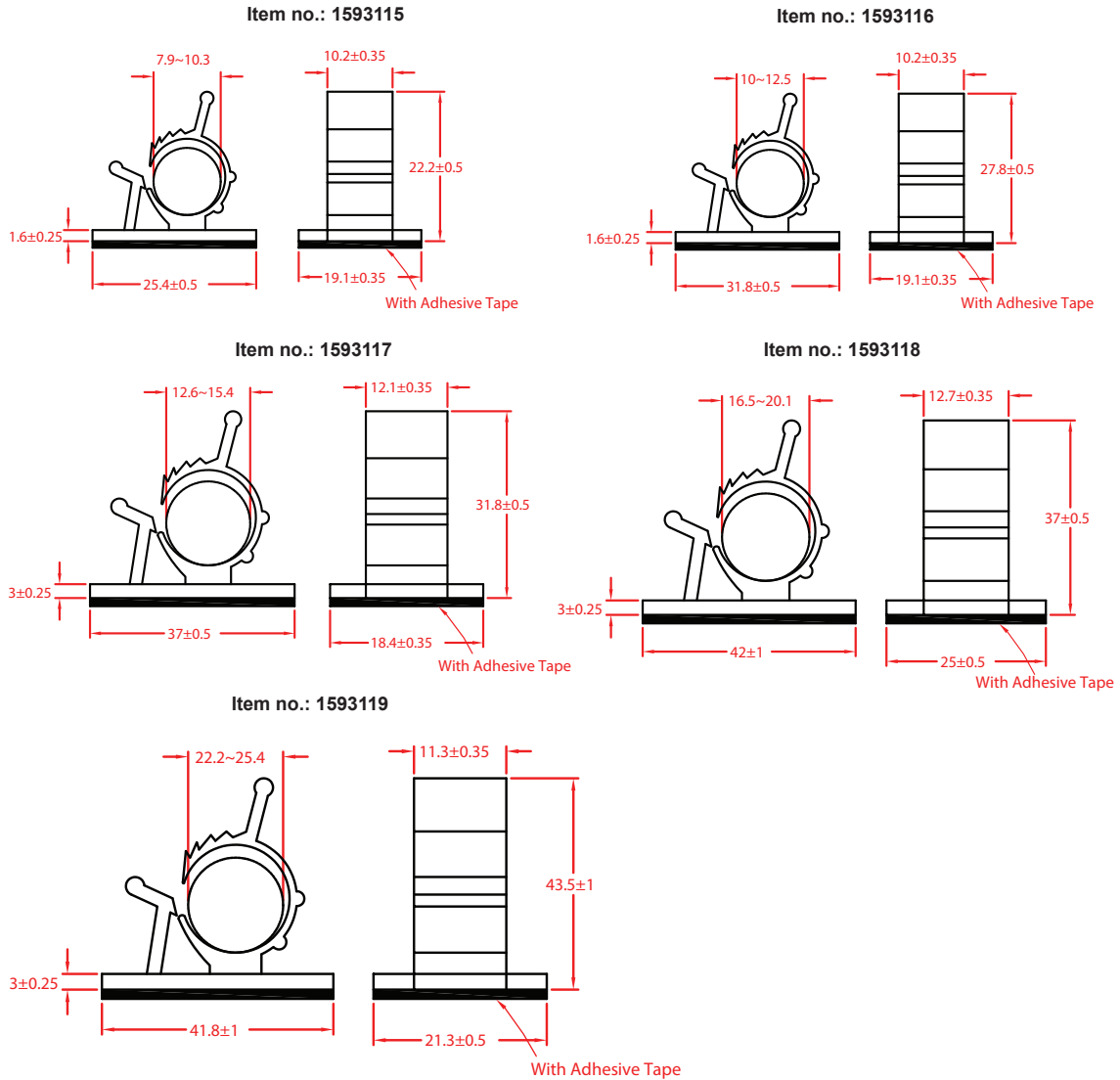

Features

- Adjustable clamp
- Easy to install

Technical data

BN	1593115	1593116	1593117	1593118	1593119
Bundle diameter range	7.9 - 10.3 mm	10 - 12.5 mm	12.6 - 15.4 mm	16.5 - 20.1 mm	22.2 - 25.4 mm
Material	UL approved Nylon 66, 94V-2				
Color	Black				
Operation temperature	-40 to +85°C				