


Data Sheet

Spiral tube

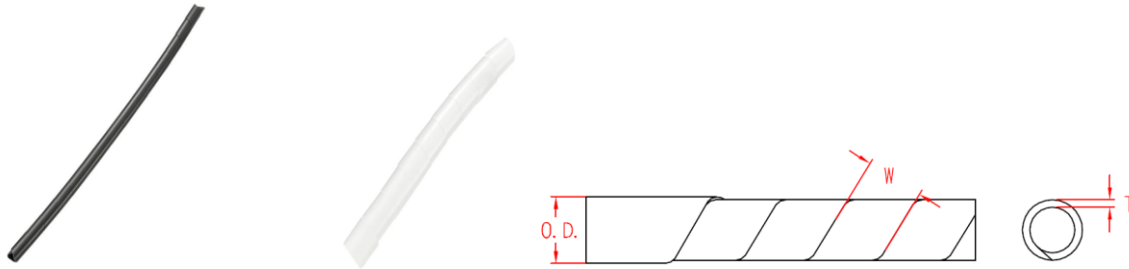

BN	O.D. (mm) – before cut in length	W (mm)	T (mm)	Bundle range (diameter- mm)	Color
1593160	10	12.3+/-1.5	0.75+/-0.1	7.5-30	Colorless
1593162	12	15+/-1.5	0.85+/-0.1	9-32	Colorless
1593164	15	15.5+/-1.5	1+/-0.2	12-35	Colorless
1593166	19	19.2+/-1.5	1.2+/-0.2	15-50	Colorless
1593154	3	4.7+/-1	0.5+/-0.1	1.5-10	Colorless
1593156	4.5	6.7+/-1	0.6+/-0.1	2.5-15	Colorless
1593158	8	12+/-1.5	0.75+/-0.1	6-30	Colorless
1593161	10	12.3+/-1.5	0.75+/-0.1	7.5-30	Black
1593163	12	15+/-1.5	0.85+/-0.1	9-32	Black
1593165	15	15.5+/-1.5	1+/-0.2	12-35	Black
1593167	19	19.2+/-1.5	1.2+/-0.2	15-50	Black
1593169	24	21.5+/-2	1.3+/-0.2	20-100	Black
1593155	3	4.7+/-1	0.5+/-0.1	1.5-10	Black
1593157	4.5	6.7+/-1	0.6+/-0.1	2.5-15	Black
1593159	8	12+/-1.5	0.75+/-0.1	6-30	Black

Material: Polyethylene (PE)