


Data Sheet

Flexible Conduit, black, dia. 7.4mm, 300M/roll

CR TYPE

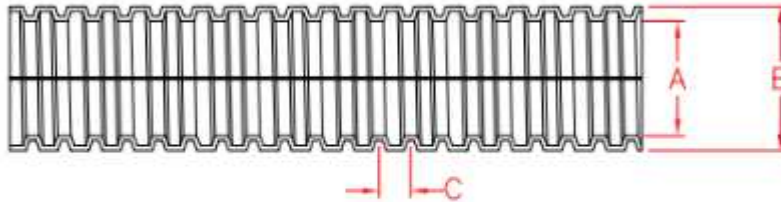

ITEM NO.	A ϕ	B ϕ	C
CR-07P	7.4 \pm 0.4	10.2 \pm 0.4	2.60

Technical data

Flexible Conduit

Total length: 300m

Inner Dia. 7.4mm, Outer Dia. 10.2mm

Material: PP

Operating temperature: 0~75°C