


T10x26 BA9s flat LED Lamp

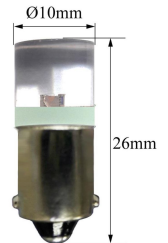

	70113711	70113713	70113714	70113715	70113722	70113726
Operating voltage DC	12 V DC					
Operating voltage AC	12 V AC					
Typ. operating current	19 mA					
Typ. power	0,23 W					
Typ. color temperature				5500 K-6300 K		3500 K-4000 K
Light color	red	green	blue	daylight	amber	white
Type of color	Red	Green	Blue	White	amber	White
Dominating wavelength	620 nm-630 nm	515 nm-525 nm	465 nm-475 nm		588 nm-598 nm	
Luminous power	0,8 lm	1,6 lm	1,1 lm	2,5 lm	0,7 lm	2,3 lm
Socket	BA9s					
Beam angle	90 °					
Height	26 mm					
Diameter	10 mm					
Average lifetime	25000 h					

	70113811	70113813	70113814	70113815	70113822	70113826
Operating voltage DC	24 V DC-28 V DC					
Operating voltage AC	24 V AC-28 V AC					
Typ. operating current	18 mA					
Typ. power	0,43 W-0,50 W					
Typ. color temperature				5500 K-6300 K		3500 K-4000 K
Light color	red	green	blue	daylight	amber	white
Type of color	Red	Green	Blue	White	amber	White
Dominating wavelength	620 nm-630 nm	515 nm-525 nm	465 nm-475 nm		588 nm-598 nm	
Luminous power	0,8 lm	1,6 lm	1,0 lm	2,6 lm	0,6 lm	2,5 lm
Socket	BA9s					
Beam angle	90 °					
Height	26 mm					
Diameter	10 mm					
Average lifetime	25000 h					

	70113911	70113913	70113914	70113915	70113922	70113926
Operating voltage AC	230 V AC					
Typ. operating current	4 mA					
Typ. power	0,92 W					
Typ. color temperature				5500 K-6300 K		3500 K-4000 K
Light color	red	green	blue	daylight	amber	white
Type of color	Red	Green	Blue	White	amber	White
Dominating wavelength	620 nm-630 nm	515 nm-525 nm	465 nm-475 nm		588 nm-598 nm	
Luminous power	0,3 lm	0,7 lm	0,2 lm	0,8 lm	0,3 lm	0,7 lm
Socket	BA9s					
Beam angle	90 °					
Height	26 mm					

	70113911	70113913	70113914	70113915	70113922	70113926
Diameter	10 mm					
Average lifetime	25000 h					