


## Datasheet

### Combined pH Electrode

No. 1599498

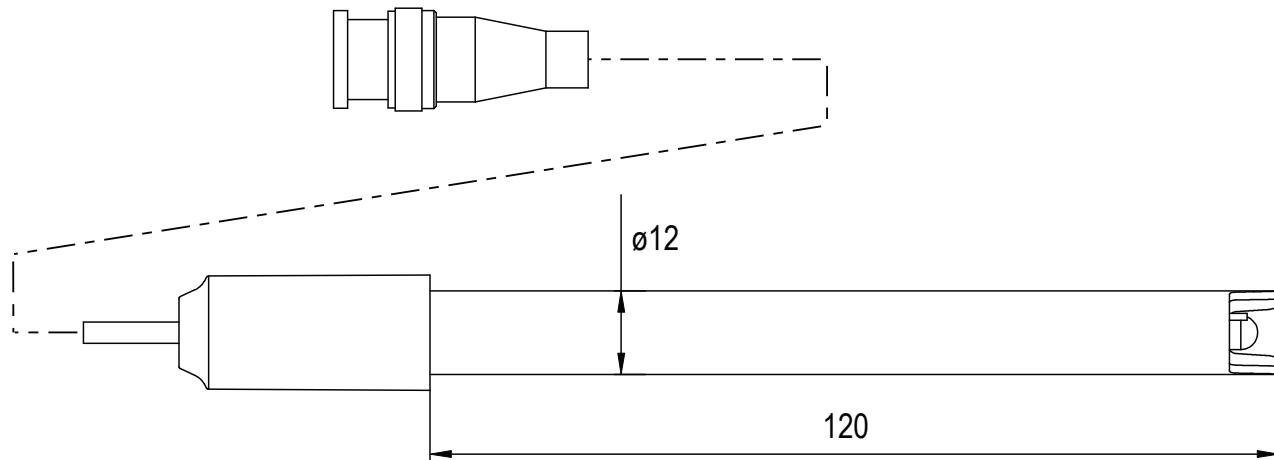

#### Technical data

pH range.....	0...14
Zero point (pH) .....	7.00 ± 0.25
Temperature range .....	0...80 °C
Temperature probe .....	--
Shaft material .....	POM
Membrane glass.....	U
Membrane resistance .....	< 250MΩ
Reference system .....	Ag / AgCl
Reference diaphragm.....	Polyester
Reference electrolyte.....	gel
Bridge electrolyte.....	--
Electrode head .....	--
Cable length .....	1.0 m
Connector.....	BNC
Cell constant ( $\text{cm}^{-1}$ ).....	--
Cell type.....	--
Indicating metal .....	--

#### Storage

Solution..... 3M KCl (51350072)