



Date	SYM	REVISION RECORD	AUTH	DR.	CK.
03/15/13	A	UPDATED TO ROHS 2 COMPLIANT	T.B.	B.S.	
06/14/13	B	UPDATED TITLE	T.B.	B.S.	
07/07/17	B	UPDATED NOTES	T.B.	B.S.	

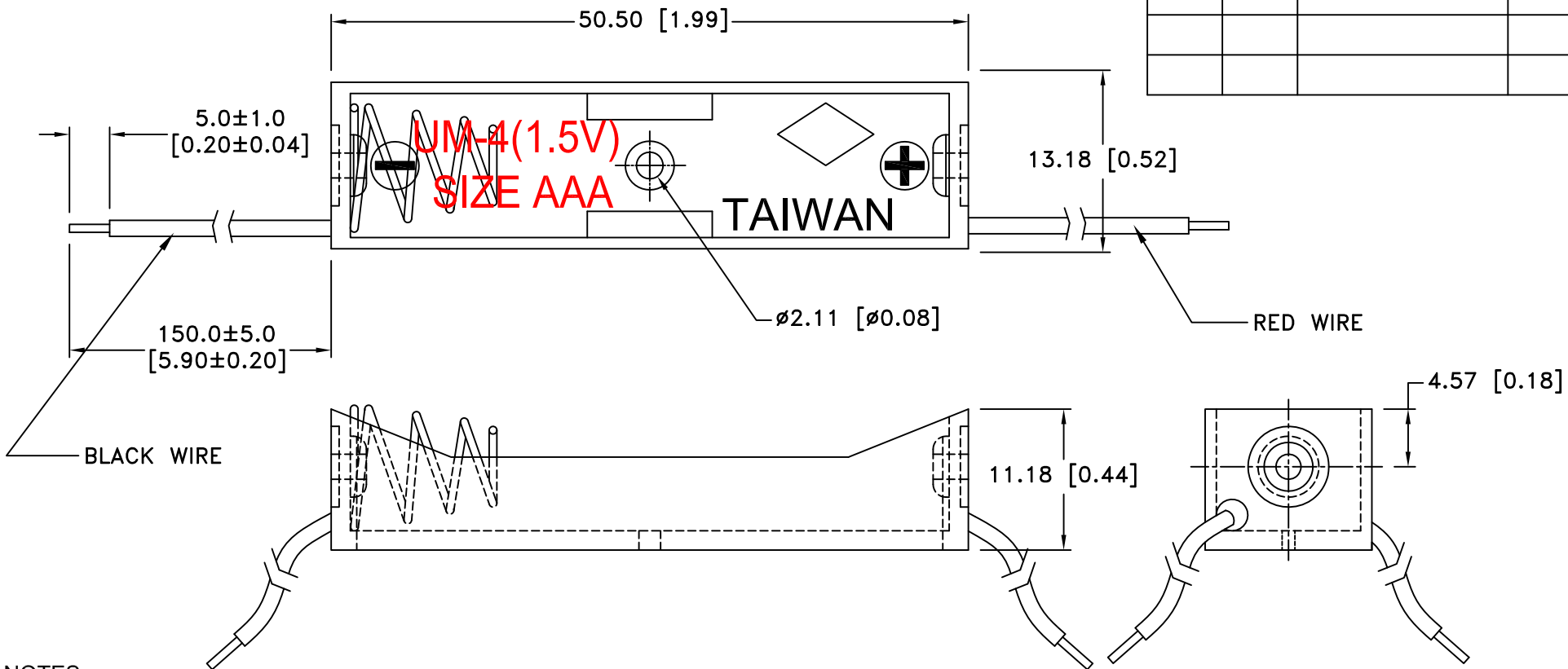

**NOTES:**

Plastic material - Polypropylene  
 Flammability Rating -UL94-HB, UL File NO. E216959  
 Temperature Range: -10°C to +100°C  
 Springs - Nickel Plated Spring Steel  
 Wire - 26 AWG, UL1007, CSA, TR64, 300V, 48°C  
 Rivets - Brass, Nickel Plated  
 CONTACT RESISTANCE: UNDER 50mΩ FOR +/- CONTACTS PER EIA-540J000  
 ROHS 2 COMPLIANT

Mounting Instruction:  
 Use 2-56 machine screws or eyelets 0.089" OD by 0.15" flange stimpson GS-3 series or equivalent. also adhesives and double sided tapes work well.

Tolerance (Except as noted)	 <b>Memory Protection Devices, Inc</b> 200 Broad Hollow Road, Farmingdale, New York 11735	Scale	Drawn By B.S.
			Approved By T.B.
decimal ±.5 (.020)	Title ONE "AAA" CELL HOLDER WITH WIRE LEADS		
Fractional ± .8 (.030)		Date 07/07/17	Drawing Number BCAAAW
Angular ± 3°			