


IG-52GM

01 & 02 TYPE



外形尺寸 / Appearance Size

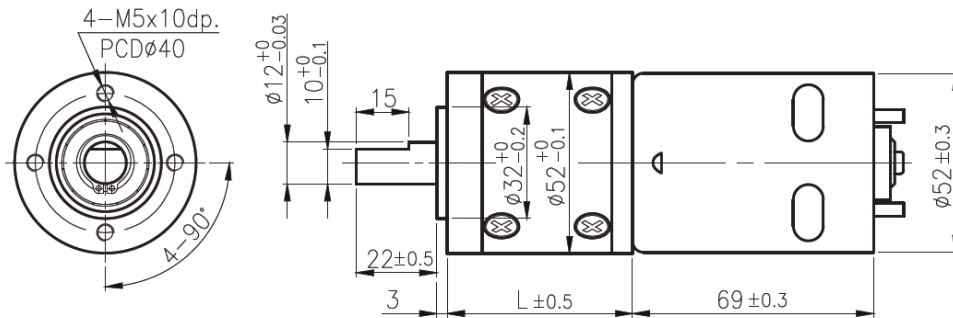

unit:mm

齒輪馬達轉矩 & 速度 / Geared Motor Torque & Speed

減速比 Reduction ratio	1/3	1/4	1/12	1/15	1/19	1/43	1/53	1/66	1/81	1/100	1/113	1/150	1/230	1/285	1/353	1/488	1/546	1/676		
12V 定格扭力 Rated torque (Kg-cm)	1.3	1.65	4.1	5	6.3	12	15	19	23	28	32	36	55	68	84	100	100	100		
12V 定格轉數 Rated speed (rpm)	1560	1260	450	369	305	130	105	85	68.5	55.5	49.5	37	24	19.5	15.5	11.5	10.4	8.3		
24V 定格扭力 Rated torque (Kg-cm)	1.8	2.2	5.5	6.8	8.5	16	20	25	31	39	44	48	74	92	100	100	100	100		
24V 定格轉數 Rated speed (rpm)	1520	1230	444	359	290	127	102	83	66.5	54	48	36	23.5	19	15.5	11.6	10.5	8.4		
軸心迴轉方向 Rotation direction	CW																			
長度 Length (L)	53		68.5				84				99.5									

Datasheet



Item no. 1601553 /1601554

V1_03122018_01_en

馬達單體型式/ Motor Data

定格電壓 Rated volt (V)	定格扭力 Rated torque (g-cm)	定格轉數 Rated speed (rpm)	定格電流 Rated current (mA)	無負荷轉數 No load speed (rpm)	無負荷電流 No load current (mA)	定格出力 Rated output (W)	重量 Weight (g)
12	480	5600	≤ 5600	6000	≤ 1750	58.6	480
24	650	5450	≤ 2750	6000	≤ 750	48.3	480

馬達單體特性/ Motor Characteristics

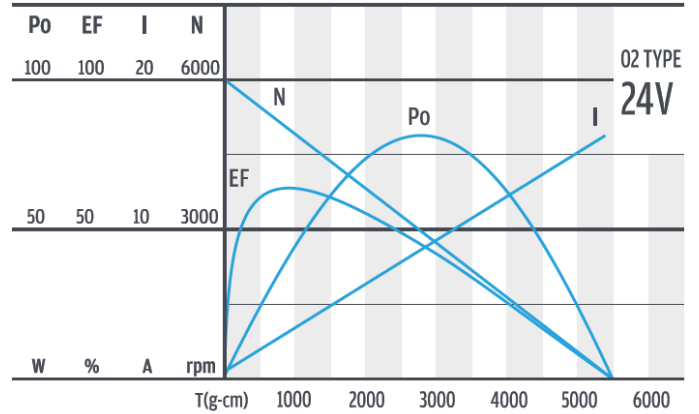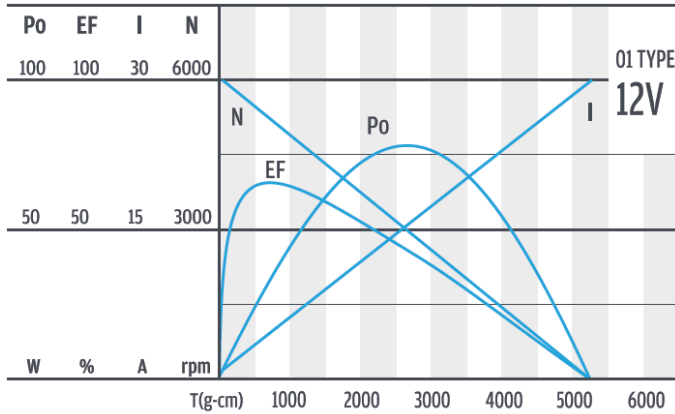

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.