


Item no.: 1601554

Data Sheet

Revision: 15 Feb 2024

24 V Gear Motor

- Appearance size

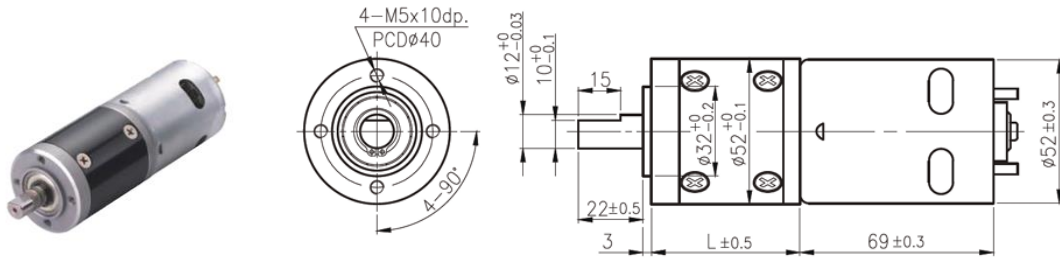

unit:mm

- Geared Motor Torque & Speed

Reduction ratio	1/3	1/4	1/12	1/15	1/19	1/43	1/53	1/66	1/81	1/100	1/113	1/150	1/230	1/285	1/353	1/488	1/546	1/676	
24 V																			
Rated torque (Kg-cm)	2.2	2.8	6.9	8.6	10.7	21.4	25.9	32.1	39.7	49	55	61.1	93.7	100	100	100	100	100	
Rated speed (rpm)	1423	1149	406	328	265	113	93	75	61	49	44	33	21	17.9	14.7	10.9	9.8	8	
Rotation direction	CW																		
Length (L)	53			68.5			84			99.5									

- Motor Data

Rated volt (V)	Rated torque (g-cm)	Rated speed (rpm)	Rated current (A)	No load speed (rpm)	No load current (A)	Rated output (W)	Weight (g)
24 V	815	4983	≤3.6	6000	≤0.6	41.7	480

- Motor Characteristics

