

GP Batteries

PRODUCT SPECIFICATION

GP Portable PowerBank Model : 4H03

Revision History

Revision	Date	Initiator	Reason for Change
0.0	2 Oct 2015	Simon Ip	Initial Draft
0.1	8 Jan 2016	Simon Ip	Remove 'preliminary' watermark
0.2	14 Jan 2016	CC Li	Add Remark for the battery rating
0.3	1 Nov 2016	CC Li	Change the product ID and LED indication
0.4	30 Nov 2016	CC Li	Update the product image

Prepared By	Approved By
CC Li	Patrick Lee
Date: 30 Nov, 2016	Date: 30 Nov, 2016


GPI International Limited

Gold Peak Building, 8/F, 30 Kwai Wing Road,
Kwai Chung, New Territories, Hong Kong.
Tel: (852) 2484 3333 Fax: (852) 24805912
Email: gpi@goldpeak.com
Website: <http://www.gpbatteries.com>

GP Batteries

Product Specification

Model no.: 4H03

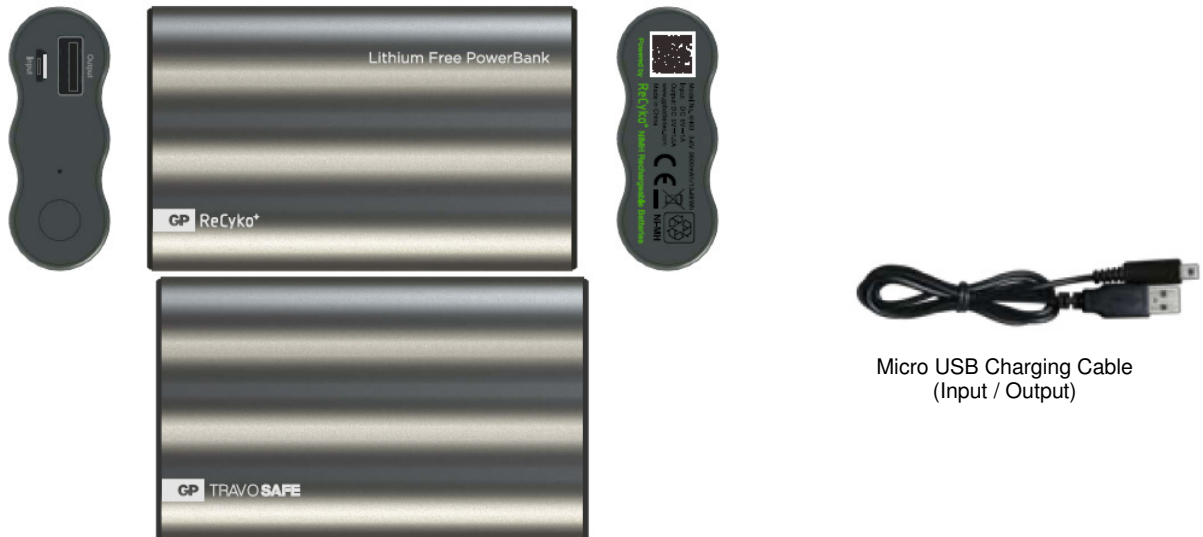

Product Name	:	GP TRAV O SAFE ReCyko+ PowerBank 4H03
Description	:	Back up power for USB powered mobile devices
Battery Rating	:	NiMH 3.6V 3800mAh / 13.68Wh
Input	:	D.C. 5V / 1A
Output	:	D.C. 5V / 1.5A
Application	:	Charge Apple iPhone, Samsung mobiles and USB powered electronic devices
Recharging Time	:	5 hr (approx.) at input voltage = 5V, average input current = 0.8A
Discharging Time	:	1.5 hr (approx.) at output voltage 5V, output current = 1.5A (The discharging time may vary for different devices)
Operation Temperature	:	0°C to 40°C
Safety protection	:	1) Over and under temperature protection 2) Over current protection 3) Over charging protection 4) Over discharging protection 5) Short circuit protection

GP Batteries

Product Specification

Model no.: 4H03

LED Indication (Charging & Discharging the ReCyKo+ PowerBank)

Charging	Green LED Slow Flashing		
Discharging / Press Button	Battery Strength	LED Indicator	Remark
	Good	Green LED on	No need for recharging
	Weak	Red LED on	May need to be recharged
Fully charged	Green LED on		
Errors	Red LED fast flashing		

Dimensions : 97 (L) x 59.4 (W) x 22.8 (H) mm

Weight : 222g +/- 5g (approx.)

Certification : CE, FCC

Warranty Period : 12 months from ex-factory date



Member
Gold Peak Group

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.