


Datasheet

Item no. 1605951 – Red 1605952 – Green
 1605953 – Blue 1605954 – White

V1_11172017_01_en

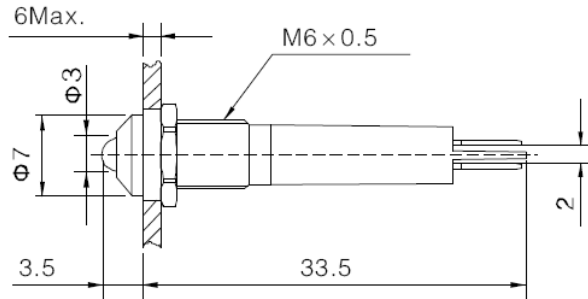

6 MAX: means the panel thickness, the max thickness for the panel no more than 6mm.

LED Indicator

Mounting Diameter	:6 mm
LED colour	:b/n 1605951 – Red b/n 1605952 – Green b/n 1605953 – Blue b/n 1605954 – White
LED Voltage	:24V AC/ DC
Forward Current	:25 mA
Forward Voltage	:2.1 V – Red 3.1 V – Green/ Blue/ White
Light Intensity	:b/n 1605951 – 80 mcd b/n 1605952 – 150 mcd b/n 1605953 – 60 mcd b/n 1605954 – 350 mcd
Head Shape	:Domed
Body Material	:Stainless Steel
Base Material	:PA
LED Life	:40,000 hours
Operating & Storage Temperature	:-20°C to 55°C
Operating & Storage Humidity	:45 -85% RH

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.