

D-Sub Full Metal, Side cable entry with Metalized Grommet Set


TECHNICAL SPECIFICATIONS

Material: Zinc, Nickel Plated
 Operating Temperature: -40°C to +120°C
 Cable Entry: Side Entry
 Thumbscrews: UNC 4-40 (Standard)
 M2,5 or M3 on request
 Cable O.D: Up to 11,5mm



Features:


- Available in sizes 9-15-25-37
- Excellent EMI Shielding
- Re-openable
- Strain relief inserts ensure a secure termination
- Jackscrew with Black Plastic Knob as standard. Grey Plastic Knob available on Request.

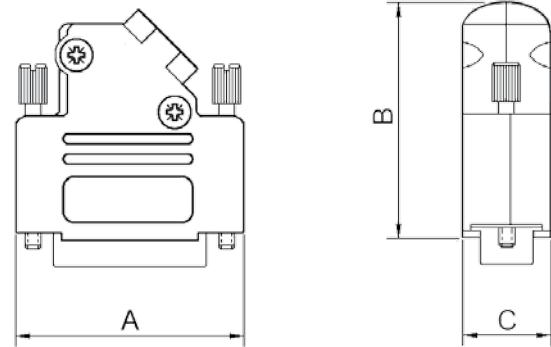

Grommet Sizes D45ZK:



 Size 9-15-25-37



Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0706-11	D45ZK09-HI-K
15-way	6560-0706-12	D45ZK15-HI-K
25-way	6560-0706-13	D45ZK25-HI-K
37-way	6560-0706-14	D45ZK37-HI-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0706-11	D45ZK09-HI
15-way	6561-0706-12	D45ZK15-HI
25-way	6561-0706-13	D45ZK25-HI
37-way	6561-0706-14	D45ZK37-HI