

## DinO One D

### Description:


- Installation on DIN rail, one module wide (17.5 mm.)
- Its small size allows mounting in existing cabinets with little space available
- Lateral sphere easy to program by movable trippers
- Switch for manual control with three positions: automatic, permanent on and permanent off
- Sealable clear window to avoid unauthorised handling
- Minimum operation time 15 minutes

### Technical specifications:

Power supply:	230 Va.c., 50-60 Hz;
Simple contact:	N/O
Switching capacity:	16 (4) A / 250 Va.c.
Programming	Daily / 15 min.
Max. Recomm. Load	Incandescent 2500 W
	Fluorescent 1200 VA
	Halogen 12 Va.c. 2000 VA
	Halogen 230 Va.c. 2500 W
	Low Consumption 900 VA
	LED 1000 VA
Max. cross section:	4 mm <sup>2</sup>
Protection degree:	IP 20 according to EN 60529
Operating temp.:	-10 °C to +45 °C according to EN 60730-2-7



ESQUEMA DE DIMENSIONES / DIMENSIONS DIAGRAM

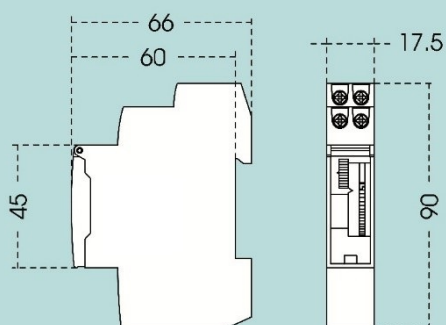

ESQUEMA DE CONEXIONES / CONNECTION DIAGRAM

