

LR44 **0%**
MERCURY

IEC:LR44
Calculator Battery

Technical Data Sheet


Specifications

Chemical system	Zinc / Manganese Dioxide, high drain
Nominal Voltage	1,50 V
Capacity	110 mAh, Discharge over 1.6 kΩ at 20°C to 1.0 V
Operating Temperature	0°C – 45°C
Self Discharge	Less than 10% per year at 20°C
Weight	~1,9 g

Dimensions


(compliant with IEC 60086)

Diameter	11,60 mm (0,457")
Height	5,40 mm (0,213")

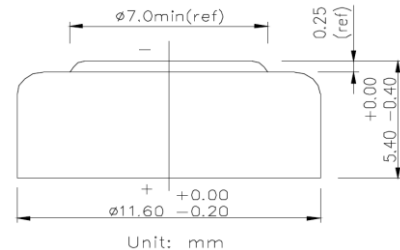

Discharge Curve

Constant Load	1.6 kΩ
Starting Drain	991 μA
Temperature	20°C

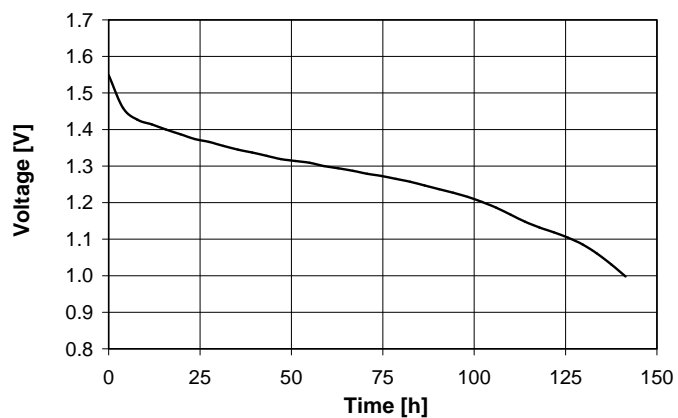

Information and contents in this data sheet are for reference purpose only. They do not constitute any warranty or representation and are subject to change without notice. For most current information and further details, please contact your Renata representative. For safety related information please consult the PSDS document related to that product or product family.

Rev. LR44MF.06 2017/07