



TC-EH 250

Electric Hoist

Item No.: 2255130

Ident No.: 11017

Bar Code: 4006825627183

The TC-EH 250 electric hoist enables the safe lifting of loads everywhere in the home, garden and workshop, simply by pressing a switch. With its numerous features this cable winch reflects the state of the art. The 12 meter wire cable with a cross-section of 3 mm can be used with a guide roller and load hook to lift a maximum load of 250 kg to a height of 5.7 m. Without the guide roller the maximum load is halved but the lifting height is increased to 11.5 m.

Features

- 12 m wire cable (twist-free, Ø 3.0 mm)
- Guide roller with load hook
- Operator switch with emergency stop function
- Motor with thermal switch
- Load hook with safety catch
- Automatic brake secures the load in every position
- Automatic limit cut-out
- Fastening with two double clamps




Technical Data

- Mains supply	230 V 50 Hz
- Max. power (S3 S3%)	500 W 20 %
- Payload without return pulley	125 kg
- Payload with return pulley	250 kg
- Lifting height without return pulley	11.5 m
- Lifting height with return pulley	5.7 m
- Hoisting speed without return pulley	8 m/min
- Hoisting speed with return pulley	4 m/min

Logistic Data

- Product weight	9.55 kg
- Gross weight single packaging	10.95 kg
- Dimensions single packaging	361 x 147 x 241 mm
- Pieces per export carton	2 Pieces
- Gross weight export carton	23.2 kg
- Dimensions export carton	376 x 305 x 250 mm
- Container quantity (20"/40"/40"HC)	1800 0 0

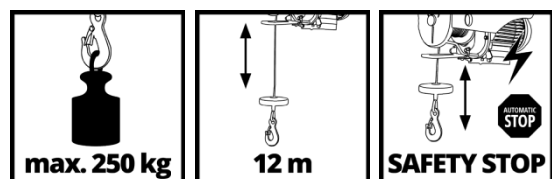

Available as special accessories



SA 1200
Hoist Lever Arm
Item No.: 2255398
Bar Code: 4006825540017
Einhell Accessory