


S spiral spring by steel with outer sheath by PVC

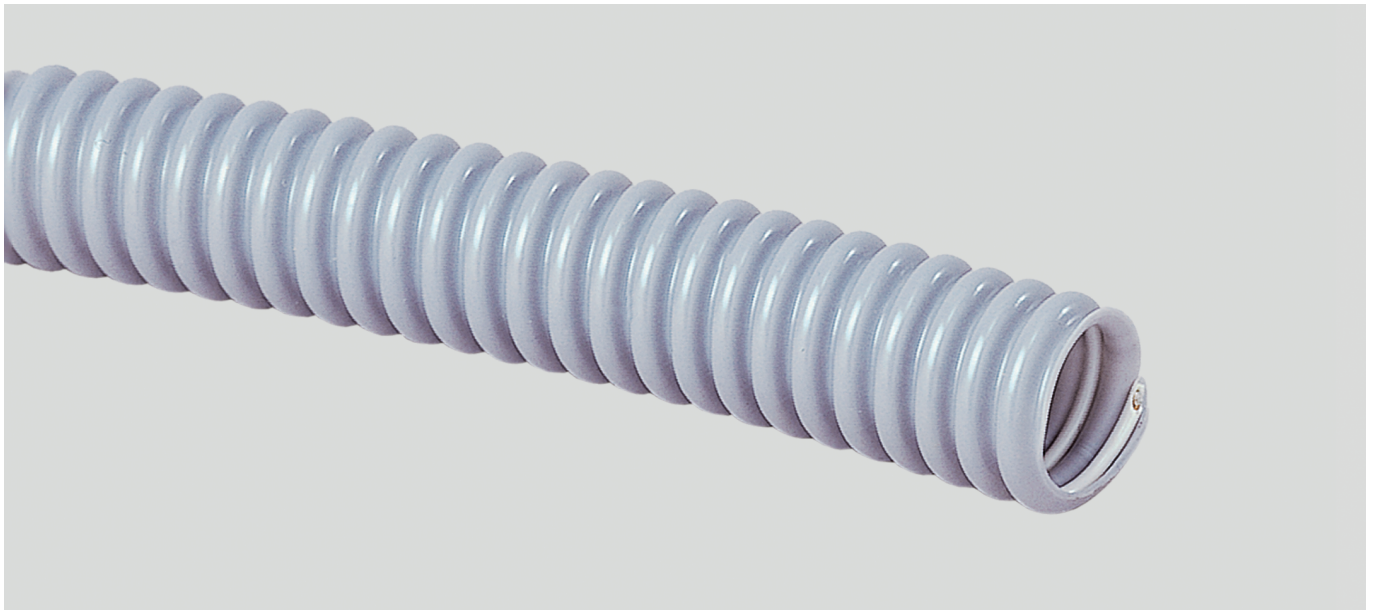

Type S

Cable protection tube type S with integrated spring steel wire, extremely flexible, expandable and compressible.

Application

- Plant and machine construction
- Automation technology
- Installation technology
- Control cabinet construction

Material

PVC

- silicone-free
- cadmium-free

Note

Suitable connection glands:
USK, LK-I, US and LI

Technical data

Temperature range: -25°C up to +80°C
Temperature range temporary up to +100°C

Part no. grey	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
91219	7,0	10,0	50	o. r.	o. r.	o. r.
91220	10,0	14,0	50	o. r.	o. r.	o. r.
91221	13,0	17,0	50	o. r.	o. r.	o. r.
91222	15,0	19,0	50	o. r.	o. r.	o. r.
91223	16,0	21,0	50	o. r.	o. r.	o. r.
91224	22,0	27,0	50	o. r.	o. r.	o. r.
91225	29,0	36,0	25	o. r.	o. r.	o. r.
91226	38,0	45,0	25	o. r.	o. r.	o. r.
91228	48,0	56,0	25	o. r.	o. r.	o. r.

small package

Part no. grey	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
91270	7,0	10,0	10	o. r.	o. r.	o. r.
91271	10,0	14,0	10	o. r.	o. r.	o. r.
91272	13,0	17,0	10	o. r.	o. r.	o. r.
91273	15,0	19,0	10	o. r.	o. r.	o. r.
91274	16,0	21,0	10	o. r.	o. r.	o. r.
91275	22,0	27,0	10	o. r.	o. r.	o. r.
91276	29,0	36,0	10	o. r.	o. r.	o. r.
91277	38,0	45,0	10	o. r.	o. r.	o. r.
91279	48,0	56,0	10	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request