


SPR-AS metal cable tubes

with latched profile

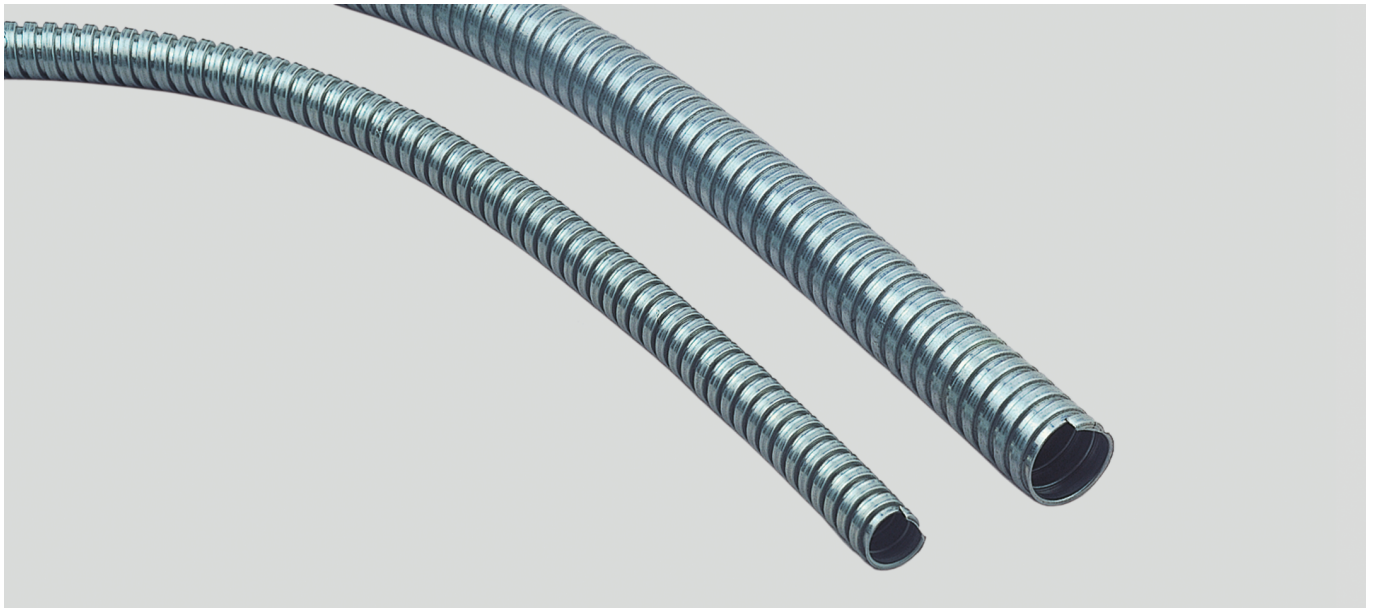

Type SPR-AS

Spiral wound metal sleeve with hooked profile.
High tensile and transverse pressure load rating.

Material

Cold strip DC 03 acc. to EN10139, galvanised,
Fe/Zn 3 or rustproof steel
UV-resistant

Technical data

Temperature range: up to +220°C

Application

- Plant- and machine construction
- Automation and installation technology
- control cabinet construction

Note

Suitable connection glands:
US, LI

Part no.	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
97023	8,0	10,0	50	o. r.	o. r.	o. r.
97024	11,0	14,0	50	o. r.	o. r.	o. r.
97025	14,0	17,0	50	o. r.	o. r.	o. r.
97026	16,0	19,0	50	o. r.	o. r.	o. r.
97027	18,0	21,0	50	o. r.	o. r.	o. r.
97028	23,0	27,0	50	o. r.	o. r.	o. r.
97029	31,0	36,0	25	o. r.	o. r.	o. r.
97030	40,0	45,0	25	o. r.	o. r.	o. r.
97031	51,0	56,0	25	o. r.	o. r.	o. r.

small package

Part no.	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
94880	8,0	10,0	10	o. r.	o. r.	o. r.
94881	11,0	14,0	10	o. r.	o. r.	o. r.
94882	14,0	17,0	10	o. r.	o. r.	o. r.
94883	16,0	19,0	10	o. r.	o. r.	o. r.
94884	18,0	21,0	10	o. r.	o. r.	o. r.
94885	23,0	27,0	10	o. r.	o. r.	o. r.
94886	31,0	36,0	10	o. r.	o. r.	o. r.
94887	40,0	45,0	10	o. r.	o. r.	o. r.
94888	51,0	56,0	10	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request