


SPR-EDU-AS metal cable tube with steel wire braiding

with latched profile

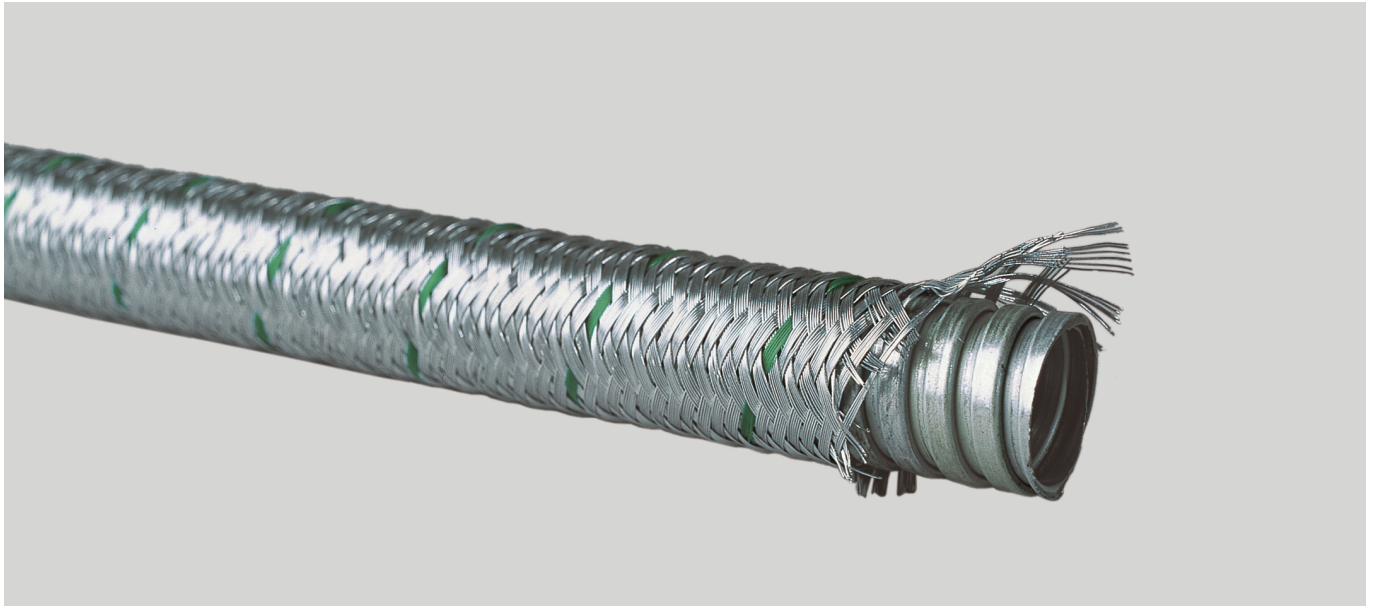

Type SPR-EDU-AS

Spiral wound metallic tube with latched profile and steel wire braiding.
High tensile and transverse pressure load rating.

Material

Cold strip DC 03 acc. to EN10139, galvanised, Fe/Zn 3 or rustproof steel
UV-resistant

Technical data

Temperature range: up to +220°C

Application

- Plant and machine construction
- Automation technology
- Installation technology
- Control cabinet construction

With steel wire braiding

Note

Suitable connection glands:
US, LI

Part no.	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
97584	7,0	10,0	50	o. r.	o. r.	o. r.
97585	10,0	14,0	50	o. r.	o. r.	o. r.
97586	13,0	17,0	50	o. r.	o. r.	o. r.
97510	15,0	19,0	50	o. r.	o. r.	o. r.
97377	17,0	21,0	50	o. r.	o. r.	o. r.
97378	22,0	27,0	50	o. r.	o. r.	o. r.
97379	29,0	36,0	25	o. r.	o. r.	o. r.
96784	38,0	45,0	25	o. r.	o. r.	o. r.
97587	49,0	56,0	25	o. r.	o. r.	o. r.

small package

Part no.	Inner Ø mm	Outer Ø mm	Per metres	Net EUR/100 metres at a purchase of		
				up to 100	101 - 500	501 - 1000
94920	7,0	10,0	10	o. r.	o. r.	o. r.
94921	10,0	14,0	10	o. r.	o. r.	o. r.
94922	13,0	17,0	10	o. r.	o. r.	o. r.
94923	15,0	19,0	10	o. r.	o. r.	o. r.
94924	17,0	21,0	10	o. r.	o. r.	o. r.
94925	22,0	27,0	10	o. r.	o. r.	o. r.
94926	29,0	36,0	10	o. r.	o. r.	o. r.
94927	38,0	45,0	10	o. r.	o. r.	o. r.
94928	49,0	56,0	10	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request